




**Cablofil**  
**FTCHC50GC Vtrough Center Hanger 50 GC**  
Part No. 343279

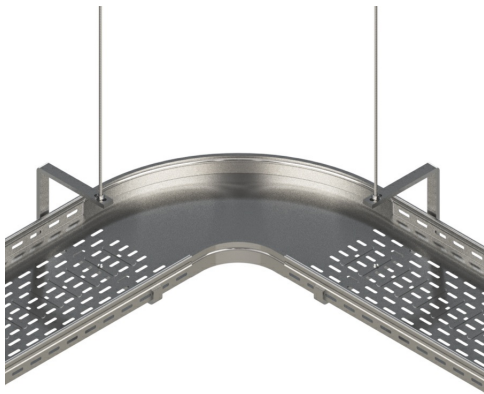

Center Hanging Fiber Trough tray makes adding cables easy with the new ESO P31. The open side allows greater access to cable pathways up to 12" wide and makes covers easier to remove and replace. Designed for medium duty loads, the ESO P31 accepts 3/8" threaded rod and attaches to the tray with EZBN1/4 bolts. ESO P31 available in EZ (Electrozinc) and GC (Hot Dipped Galvanized) to match your application environment.

## Features & Benefits

Open side allows cables to added to pathway easily  
Use with 3/8" threaded rod  
Packaged in sets of 6 and 10

Works with Fiber Trough or V-Trough Tray up to 12" wide  
Steel construction is available in two finishes.

## Specifications

### General Info

Product Line	Cablofil	Finish	Hot Dipped Galvanized
UPC Number	800388247789	Country Of Origin	France

### Dimensions

Product Width US	2.0 in	Product Height US	2.5 in
------------------	--------	-------------------	--------

### Buy American Act Compliance

BAA	Yes
-----	-----