




adorne Collection
adorne® 15A Energy-Saving On/Off Outlet, White
Part No. ARPS152W4

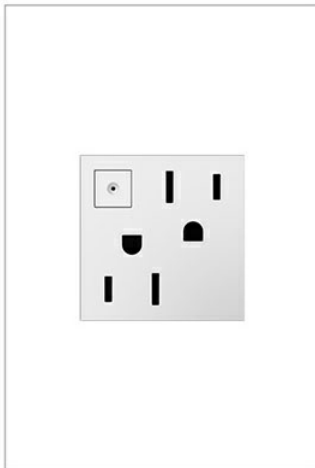

Add stunning, modern style with this outlet from the adorne Collection, while conserving energy when it's not in use. It allows you to stop the flow of power whenever you don't need it, for easy energy management. Made exclusively for use with screwless Wall Plates from the adorne® Collection, sold separately.

Features & Benefits

GETTING STARTED: For complete installation, device must be paired with an adorne® screwless Wall Plate (not included). Available in a range of contemporary colors and stunning finishes.

Cut power to the outlet when not in use to conserve energy.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

Installs in 15 minutes or less, fitting into an existing electrical box. No new wiring required for typical installation.

Protects children with a patented tamper-resistant shutter system that prevents improper insertion of foreign objects, complete with "invisi-shutters" for an invisible effect.

Specifications

General Info

Product Line	Pass & Seymour	Color	White
Finish	Matte	Country Of Origin	China
Number of Receptacles	2	Outlet Type	Energy Saving On/Off, Indoor, Residential, Tamper-Resistant
Application Sector	Residential	Standard	CULUS
Warranty Type	Limited Lifetime Warranty	Type	Outlet

Dimensions

Product Width US	2.66 in	Product Depth US	1.73 in
------------------	---------	------------------	---------

Product Height US 1.77 in

Technical Information

Phase Single Connection Side and Back Wire

Number of Wires 3 Number of Gangs 1

Amperage 15 A Number of Poles Double Pole

Wire Size 14 - 10 AWG Indoor/Outdoor Indoor

NEMA Configuration Code 5-15R Mounting Type Box

Voltage 125.0 V Connection Type Internal Pressure Plates

Environmental Conditions 95% (relative humidity, non-condensing)
