
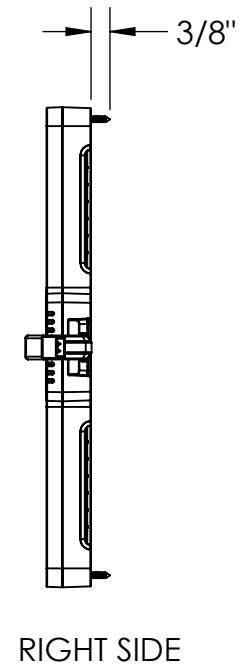
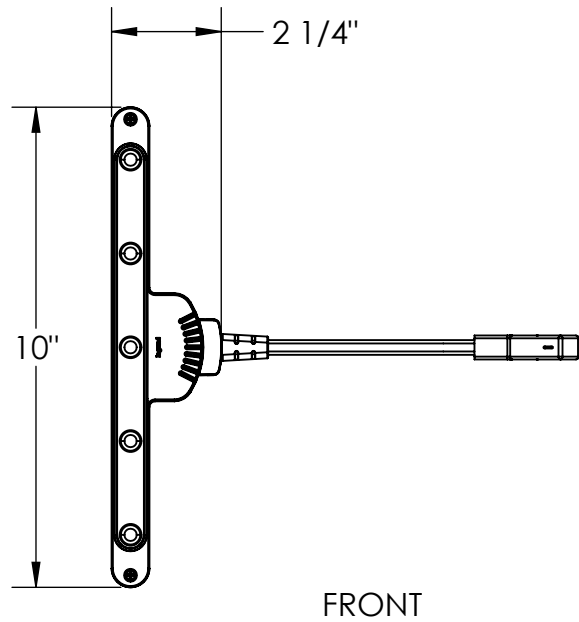
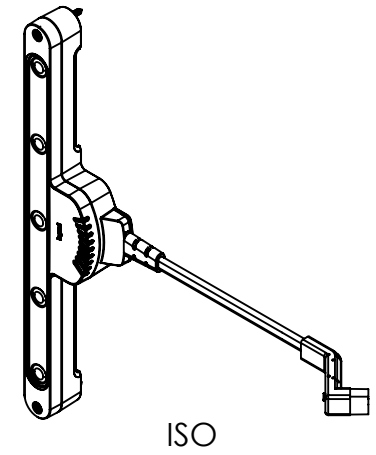


ALPKLED SPECIFICATION	
PARAMETER	VALUE
OPERATING VOLTAGE	120V
LINE FREQUENCY	50/60 HZ
LUMEN OUTPUT	280 lm \pm 30 lm
BEAM ANGLE	90~120°
COLOR TEMPERATURE	2925K \pm 50
COLOR-RENDERING INCES (CRI)	95
INPUT POWER	8W
RELIABILITY STANDARD	IEC STANDARD
LIFETIME	40,000 HRS
NOISE LEVEL AT 12 INCHES	24dBA
TRIAC DIMMABLE, INDOOR USE, MEETS ROHS AND UL	

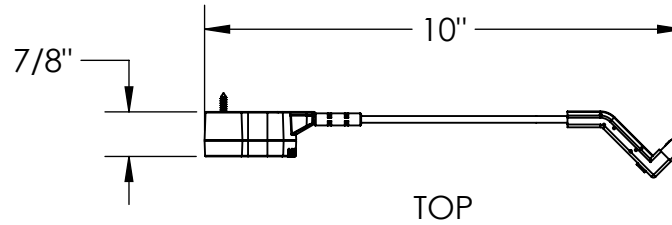

Legrand
 SYSTEM: Under Cabinet SLighting system
 CATALOG NUMBER: ALLNLED
 9/05/12