

- AN INDUSTRY EXCLUSIVE -

## charge like never before

The new Qi-certified radiant Wireless Charger, the first of its kind, instantly provides a revolutionary new way to charge your phone.

### EASY INSTALLATION

Designed to replace any standard, single gang outlet using existing electrical wiring

### FAREWELL, POWER CORDS

Qi charging technology cuts the cord for your devices - finally, they are truly wireless




## FEATURES

- **Tamper-resistant duplex receptacles meet NEC** to meet NEC. Patented shutter system - now with black "invisi-shutters" for an invisible effect - helps prevent improper insertion of foreign objects

- **Combination Duplex receptacle** includes one 5-volt DC USB port that work with USB 2.0 and 3.0 devices

- **The wireless charge plate** provides a convenient charging cradle that wirelessly charges all Qi compatible devices

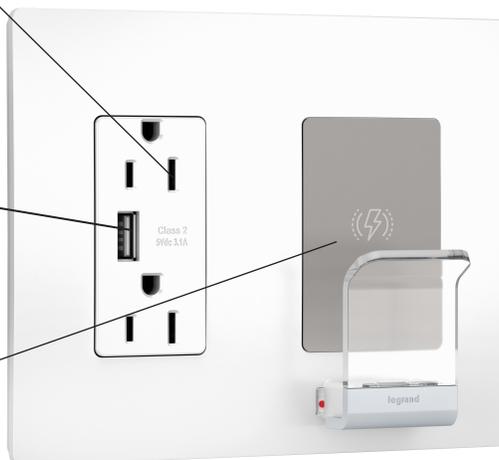

- **Back and side wiring terminals** for installation flexibility: accommodates #14 AWG - #10 stranded copper wires

- **Available in multiple colors:** White, Ivory, Light Almond and Black

- **Overall 3.1A charging capability**



- **Qi certification** ensures a safe, reliable wireless charging experience

RWC826USBWCCV2

PRODUCT INFORMATION

ELECTRICAL	
<b>Dielectric Withstand Voltage:</b>	Withstands 1500V minimum
<b>Maximum Working Voltage:</b>	125V
<b>Current Interrupting:</b>	Certified for current interrupting at full-rated current (receptacle only)
MECHANICAL	
<b>Terminal Accommodation</b>	Back and side wire terminals accommodate #14 AWG - #10 AWG stranded and solid copper wire
<b>Product Identification</b>	Ratings are a permanent part of the device
MATERIALS	
<b>Face</b>	Polycarbonate
<b>Back Body</b>	Nylon
<b>Line Contacts</b>	CDA 260 Brass
<b>Mounting Strap</b>	.049" Zinc-Plated Steel
<b>Terminal Screws</b>	Tri-Drive Zinc-Plated Steel
<b>Ground Screw</b>	Tri-Drive Steel with Green Chromate
<b>Mounting Screws</b>	Tri-Drive Steel
<b>Wall Plate</b>	Polycarbonate
<b>Input Voltage:</b>	125VAC
<b>USB Connection:</b>	5Vdc 3.1A Combined
<b>Regulatory Approvals - FCC:</b>	YV8-RWC826USB
<b>Regulatory Approvals - UL Standard:</b>	UL Listed, File Number E140596, Standard UL498, UL1310, UL514D cUL Listed, File Number E140596, CSA C22.2 No. 42-10, No. 42.1, No. 223
<b>Regulatory Approvals - Qi</b>	WPC Qi Registered, Power Class 0 Transmitter, Qi ID 2092
 <p><b>NEMA 5-15R</b></p>	Tamper Resistant
	NEMA 5-15R
	Integral LED's tell status of charging: Solid Red, Charging Solid Green, Charging Complete Blinking Red, Fault

 [LEGRAND.US/RADIANT](http://LEGRAND.US/RADIANT)



**Electrical Wiring Systems**

60 Woodlawn Street  
West Hartford, CT 06110  
1.877.BY.LEGRAND (295.3472)  
[www.legrand.us](http://www.legrand.us)

Canada  
1.800.723.5175; 905.738.9195  
[www.legrand.ca](http://www.legrand.ca)



designed to be better.™