


# SWITCHES

## radiant™ Combination Switches

### RCD113W radiant™ Combination Switches

- A. Unique “Up/Down” switches** match the look and feel of standard paddle switches.
- B. Easy-to-use oversized main switch** for primary load.
- C. Patented Snap-In Light Module** (sold separately) transforms a combination switch into an illuminated switch in seconds.
- D. Impact-resistant face and body.**
- E. Full wraparound metal strap**, commercial grade with lock-in tabs.
- F. All screws are tri-drive.**
- G. External screw-pressure-plate back and side wired.** Accepts #12 and #14 AWG.

The radiant™ collection is a step up from the standard with simple, classic options in wiring devices, home automation controls, and screwless wall plates that complement today’s homes and hospitality settings.

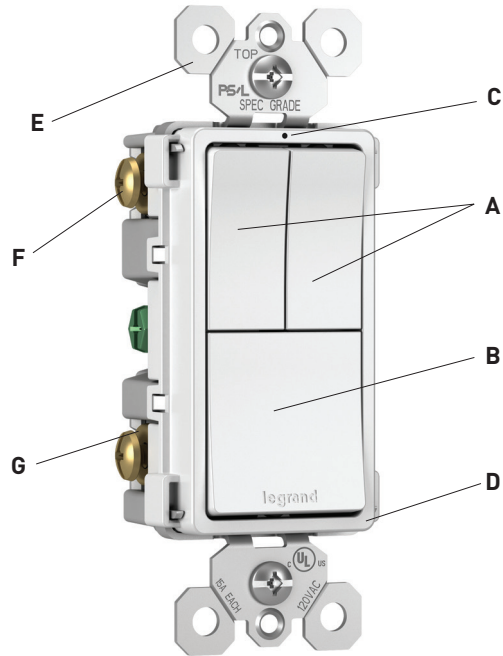


RCD113W

### Features

 - Module simply snaps-in for easy installation.

#### Snap-In Light Module:


- Lights when OFF.
- Uses energy-efficient LED light.
- LED light will not generate heat and will last, on average, 47 years.



RCDLM


CATALOG NUMBER	RATING		COLOR	3rd PARTY COMPLIANCE
	A.	VAC		cULus cULus
<b>RADIANT™ LOCATOR LIGHT MODULE</b>				
RCDLM	15	120/125	Clear	•

### Adding a Snap-In Light Module

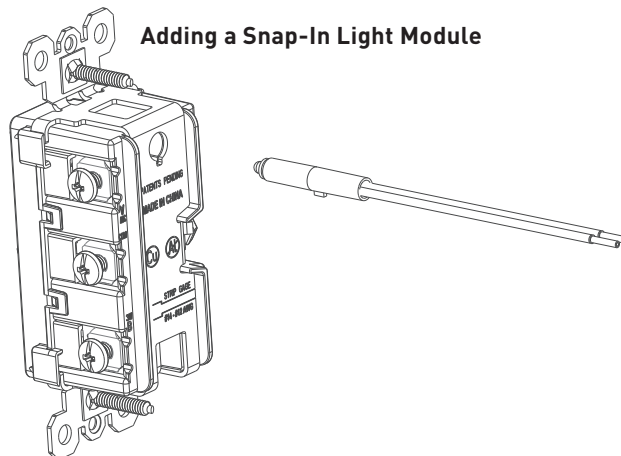


# SWITCHES


## radiant™ Combination Switches 15A, 120/125VAC

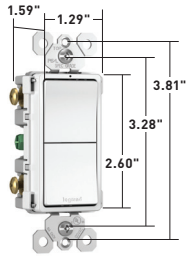


RCD11W

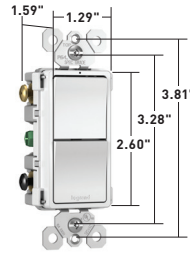

RCD33W

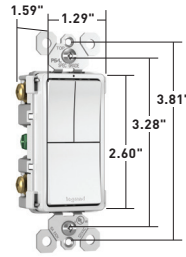

RCD113W

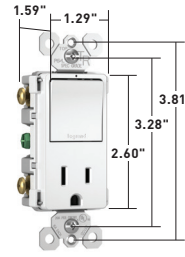

RCD38TRW

### Features

- Part of the radiant™ collection
- Impact-resistant face and body.
- External screw-pressure-plate back and side wired. Accepts #12 and #14 AWG.
- Full wraparound metal strap with lock-in tabs.
- Unique "Up/Down" switches match the look and feel of standard paddle switches.
- Largest breadth of 15 amp offering.
- All screws are tri-drive.
- Protects children: patented shutter system – now with black "invisi-shutters" that disappear for an invisible effect – helps prevent improper insertion of foreign objects.
- Single Pole/3-Way Switches can be wired as a single pole or 3-way switch.

CATALOG NUMBER	RATING		COLOR	3rd PARTY COMPLIANCE	
	A.	VAC		cUL <sup>us</sup> UL20	UL cULus
<b>TWO SINGLE POLE SWITCHES</b>					
RCD11I	15	120/125	Ivory	•	•
RCD11W	15	120/125	White	•	•
RCD11BK	15	120/125	Black	•	•
RCD11LA	15	120/125	Light Almond	•	•
<b>TWO SINGLE POLE/3-WAY SWITCHES</b>					
RCD33I	15	120/125	Ivory	•	•
RCD33W	15	120/125	White	•	•
RCD33BK	15	120/125	Black	•	•
RCD33LA	15	120/125	Light Almond	•	•
<b>TWO SINGLE POLE SWITCHES &amp; SINGLE POLE/3-WAY SWITCH</b>					
RCD113I	15	120/125	Ivory	•	•
RCD113W	15	120/125	White	•	•
RCD113BK	15	120/125	Black	•	•
RCD113LA	15	120/125	Light Almond	•	•

CATALOG NUMBER	RATING		COLOR	NEMA CONFIG. NO.	3rd PARTY COMPLIANCE		
	A.	VAC			UL UL20	UL UL498	cUL <sup>us</sup> cULus
<b>SINGLE POLE/3-WAY SWITCH &amp; TAMPER-RESISTANT SINGLE RECEPTACLE</b>							
RCD38TRI	15	120/125	Ivory	5-15R	•	•	•
RCD38TRW	15	120/125	White	5-15R	•	•	•
RCD38TRBK	15	120/125	Black	5-15R	•	•	•
RCD38TRLA	15	120/125	Light Almond	5-15R	•	•	•