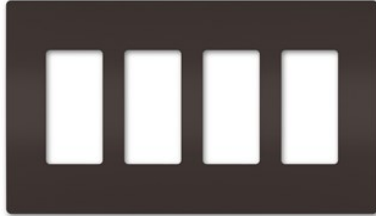

FOUR-GANG SCREWLESS WALL PLATE, BROWN

RWP264 | [radiant](#)



FEATURES & BENEFITS

A step above the standard with no unsightly screws, this modern, low-profile wall plate instantly elevates the look of radiant dimmers, switches, outlets, home automation controls and more.

Available in White, Ivory, Light Almond, Black, Brown and Gray, as well as three metallic finishes: Nickel, Dark Bronze and Antique Brass (all sold separately) to coordinate with most any decor.



- **Redesigned screwless wall plates** feature a lower, more modern profile in keeping with today's design trends.
- **Molded of rugged .065" thick polycarbonate**
- **One-piece subplate** mounts over the device for easy retrofit and lower profile.
- **Subplate screws align devices** to ensure proper positioning of the wall plate.
- **Opening accommodates all NEMA 26-opening devices.**
- **An extra 3/8" width and height than standard size wall plates** for more tolerance in covering ragged sheet rock openings.

SPECIFICATIONS

GENERAL INFO

Color: Brown

Special Features: Screwless

LISTING AGENCIES/THIRD PARTY CERTIFICATIONS

RoHS: Yes

CONSTRUCTION INFORMATION

Component 4: 78500723199

DIMENSIONS

Height (US): 4.94"

Width (US): 8.59"

TECHNICAL INFORMATION

Material: Polycarbonate

COUNTRY OF ORIGIN

Country Of Origin: UNITED STATES OF AMERICA