




Ortronics
Infinium Fusion Splice-On Connector, SC, OM4, magenta 900 micron boot, packaged in boxes
Part No. 205KNF9FA-50E

..

Splice-On Connector SC PC OM4

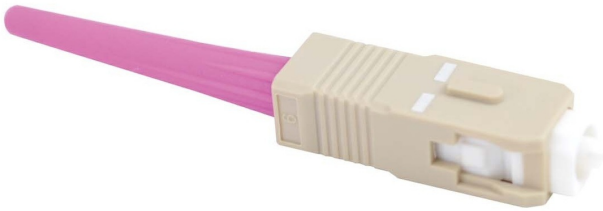

Features & Benefits

Better Insertion Loss & Return Loss Performance: Support high-bandwidth/high-speed transmission to 25G, 40G and 100G applications	Factory-cleaved, pre-polished 900-micron fiber stub: Provides a quicker termination
Available in LC, SC and ST, Single-Mode or Multimode: Multiple connector types available	900-micron boot conceals and protects the splice: Enables better cable management
UV Cure Protection Sleeves: Strain relief boot protects the splice point	3mm Version: 3mm boot protects splice for easy cable management
3mm Version: Brass crimp to protect splice	3mm Version: Tubing insert to accommodate 1.6/2.0/3.0 cordage

Specifications

General Info			
Product Line	Ortronics	UPC Number	662875849254
Country Of Origin	United States		
Dimensions			
Product Width US	2.46 in	Product Depth US	2.46 in
Product Height US	0.4 in		