


“
 Splice-On Connector SC PC OM3

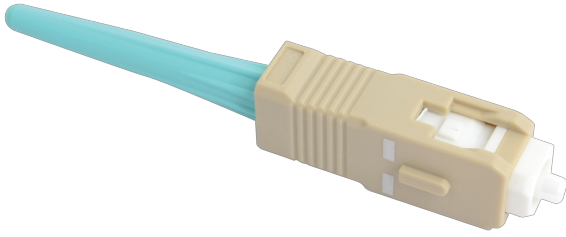

Features & Benefits

- Better Insertion Loss & Return Loss Performance: Support high-bandwidth/high-speed transmission to 25G, 40G and 100G applications
- Factory-cleaved, pre-polished 900-micron fiber stub: Provides a quicker termination
- Available in LC, SC and ST, Single-Mode or Multimode: Multiple connector types available
- 900-micron boot conceals and protects the splice: Enables better cable management
- UV Cure Protection Sleeves: Strain relief boot protects the splice point
- 3mm Version: 3mm boot protects splice for easy cable management
- 3mm Version: Brass crimp to protect splice
- 3mm Version: Tubing insert to accommodate 1.6/2.0/3.0 cordage
- Fiber endface types: Endfaces available in PC, APC and UPC

Specifications

General Info

Product Line	Ortronics	UPC Number	662875849070
Country Of Origin	China		

Dimensions

Product Width US	2.46 in	Product Depth US	2.46 in
Product Height US	0.4 in		