




Pass and Seymour
Trademaster® 15A 125V Self-Grounding Tamper-Resistant Duplex Receptacle, Ivory
Part No. 3232TRSI

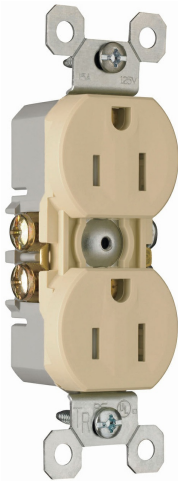

15A/125A Trademaster® Self-Grounding, Tamper-Resistant Duplex Receptacle

Features & Benefits

Quality Materials, durability, and time-tested design

Two drive screws anchor strap to back body and face where abrupt removal torque is greatest.

Specifications

General Info

Product Line	Pass & Seymour	Color	Ivory
Finish	Matte	Country Of Origin	China
Number of Receptacles	2	Outlet Type	Commercial, Indoor, Residential, Self-Grounding, Tamper-Resistant
Application Sector	Residential	Standard	cULus UL498, CSA C22.2 No. 42
Type	Outlet		

Dimensions

Product Width US	1.32 in	Product Depth US	1.0 in
Product Height US	3.31 in		

Listing Agencies / 3rd Party Agencies

cULus Listed	Yes
--------------	-----

Additional Information

Product Environmental Profile Yes

Technical Information

Is Tamper-Resistant Yes Temperature Rating -30° - 60° C

Amperage 15 A Number of Poles Double Pole

Wire Size 14 - 12 AWG Indoor/Outdoor Indoor

Voltage 125.0 V
