




Cablofil  
FTCHC200GC Vtrough Center Hanger 200 GC  
Part No. 343282

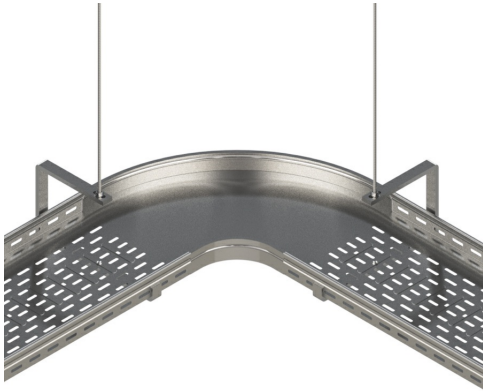

Center Hanging Fiber Trough tray makes adding cables easy with the new ESO P31. The open side allows greater access to cable pathways up to 12" wide and makes covers easier to remove and replace. Designed for medium duty loads, the ESO P31 accepts 3/8" threaded rod and attaches to the tray with EZBN1/4 bolts. ESO P31 available in EZ (Electrozinc) and GC (Hot Dipped Galvanized) to match your application environment.

## Features & Benefits

Open side allows cables to added to pathway easily

Use with 3/8" threaded rod

Packaged in sets of 6 and 10

Works with Fiber Trough or V-Trough Tray up to 12" wide

Steel construction is available in two finishes.

## Specifications

### General Info

Product Line	Cablofil	Finish	Hot Dipped Galvanized
UPC Number	800388247734	Country Of Origin	France

### Dimensions

Product Width US	8.0 in	Product Height US	5.0 in
------------------	--------	-------------------	--------

### Buy American Act Compliance

BAA	Yes
-----	-----