




Quiktron  
12ft Q-Series Cat6a Snagless (UTP) Ethernet Network Patch Cable, CM Rated - Blue  
Part No. 576-A10-012

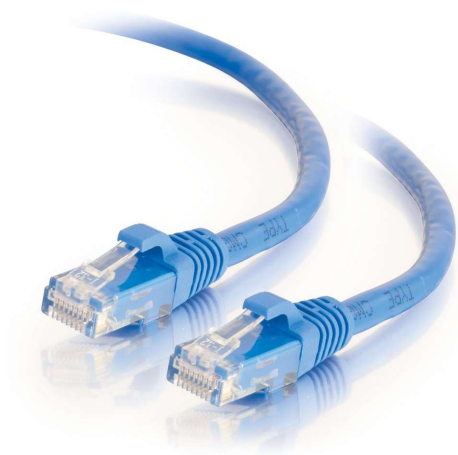

Q-Series patch cords are a perfect solution for when cost and speed of delivery are top priority. Designed to perform to TIA-568.2-D standards, Q-Series cords are available in a full range of colors and lengths, stocked and ready to order.

## Features & Benefits

Connector: 50micron gold plated RJ45 male to male	Conductor: 24AWG stranded copper
Warranty Type: Lifetime warranty	Price Sensitive: Perfect solution for when cost and speed of delivery are top priority
Standards Compliant: Perform to TIA-568.2-D standards	

## Specifications

### General Info

Product Line	Quiktron	UPC Number	884815793001
Country Of Origin	Vietnam	Application Sector	Commercial/Industrial
Type	Copper Patch Cord		

### Dimensions

Product Weight US	0.42 lb	Product Length US	12.0 FT
-------------------	---------	-------------------	---------

### Additional Information

RoHS Conformant	Yes
-----------------	-----