




Quiktron  
10ft Q-Series Cat6a Snagless (UTP) Ethernet Network Patch Cable, CM Rated - Yellow  
Part No. 576-A15-010

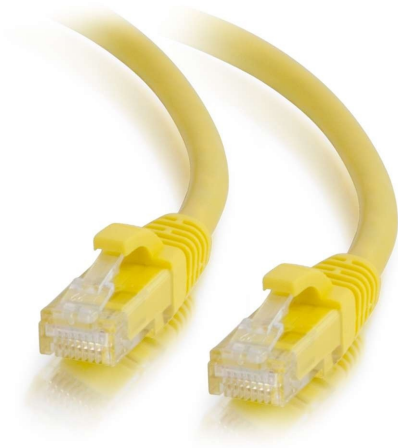

Q-Series patch cords are a perfect solution for when cost and speed of delivery are top priority. Designed to perform to TIA-568.2-D standards, Q-Series cords are available in a full range of colors and lengths, stocked and ready to order.

## Features & Benefits

Connector: 50micron gold plated RJ45 male to male

Conductor: 24AWG stranded copper

Warranty Type: Lifetime warranty

Price Sensitive: Perfect solution for when cost and speed of delivery are top priority

Standards Compliant: Perform to TIA-568.2-D standards

## Specifications

### General Info

Product Line	Quiktron	Color	Yellow
UPC Number	884815793445	Country Of Origin	Vietnam
Features	Standard Diameter	Application Sector	Commercial, Industrial
Warranty Type	5-Year	Type	Copper Patch Cord

### Dimensions

Product Weight US	0.35 lb	Product Length US	10.0 FT
Cable Length	10 ft		

### Additional Information

---

RoHS Compliant	Yes	Product Environmental Profile	Yes
----------------	-----	-------------------------------	-----

---

## Technical Information

---

Operating Temperature Min	-10 °C	Category Performance Application	Cat6a
---------------------------	--------	----------------------------------	-------

---

Compatibility	RJ-45	Wire Gauge	24 AWG
---------------	-------	------------	--------

---

Storage Humidity	0-90% RH (Non-Condensing)	Plating Specification	50 μ in Gold
------------------	---------------------------	-----------------------	--------------

---

Jacket Application	Riser Rated	Bend Radius	0.944 in
--------------------	-------------	-------------	----------

---

Shielded/Unshielded Cable	Unshielded	Termination Style	Pre-Terminated
---------------------------	------------	-------------------	----------------

---

Conductor Stranding	Stranded	Operating Temperature Max	60 °C
---------------------	----------	---------------------------	-------

---

Cable Type	Snagless	Jacket Rating	CM Rated
------------	----------	---------------	----------

---

Cable Diameter	0.236 in	Braid	Non-braided Wiring
----------------	----------	-------	--------------------

---

Connector 2	RJ-45 Male	Connector 1	RJ-45 Male
-------------	------------	-------------	------------

---

Operating Temperature	-10°-60°C	Operating Humidity	0-90% RH (Non-Condensing)
-----------------------	-----------	--------------------	---------------------------

---

Number of Strands	7	Conductor Material	Copper
-------------------	---	--------------------	--------

---

Voltage	300.0 V	Storage Temperature	-40° - 60° C
---------	---------	---------------------	--------------

---