




Quiktron
14ft Q-Series Cat6a Snagless (UTP) Ethernet Network Patch Cable, CM Rated - Yellow
Part No. 576-A15-014

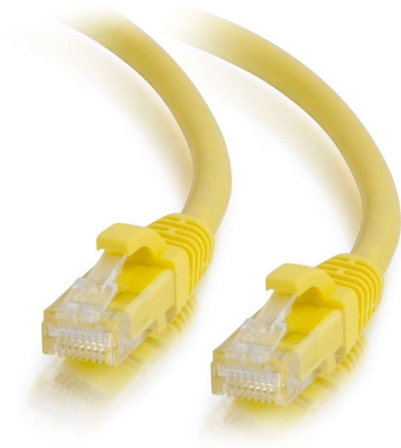

Q-Series patch cords are a perfect solution for when cost and speed of delivery are top priority. Designed to perform to TIA-568.2-D standards, Q-Series cords are available in a full range of colors and lengths, stocked and ready to order.

Features & Benefits

Connector: 50micron gold plated RJ45 male to male

Conductor: 24AWG stranded copper

Warranty Type: Lifetime warranty

Price Sensitive: Perfect solution for when cost and speed of delivery are top priority

Standards Compliant: Perform to TIA-568.2-D standards

Specifications

General Info

Product Line	Quiktron	Color	Yellow
UPC Number	884815793469	Country Of Origin	Vietnam
Features	Standard Diameter	Application Sector	Commercial, Industrial
Warranty Type	5-Year	Type	Copper Patch Cord

Dimensions

Product Weight US	0.49 lb	Product Length US	14.0 FT
Cable Length	14 ft		

Additional Information

RoHS Compliant	Yes	Product Environmental Profile	Yes
----------------	-----	-------------------------------	-----

Technical Information

Operating Temperature Min	-10 °C	Category Performance Application	Cat6a
---------------------------	--------	----------------------------------	-------

Compatibility	RJ-45	Wire Gauge	24 AWG
---------------	-------	------------	--------

Storage Humidity	0-90% RH (Non-Condensing)	Plating Specification	50 μ in Gold
------------------	---------------------------	-----------------------	--------------

Jacket Application	Riser Rated	Bend Radius	0.944 in
--------------------	-------------	-------------	----------

Shielded/Unshielded Cable	Unshielded	Termination Style	Pre-Terminated
---------------------------	------------	-------------------	----------------

Conductor Stranding	Stranded	Operating Temperature Max	60 °C
---------------------	----------	---------------------------	-------

Cable Type	Snagless	Jacket Rating	CM Rated
------------	----------	---------------	----------

Cable Diameter	0.236 in	Braid	Non-braided Wiring
----------------	----------	-------	--------------------

Connector 2	RJ-45 Male	Connector 1	RJ-45 Male
-------------	------------	-------------	------------

Operating Temperature	-10°-60°C	Operating Humidity	0-90% RH (Non-Condensing)
-----------------------	-----------	--------------------	---------------------------

Number of Strands	7	Conductor Material	Copper
-------------------	---	--------------------	--------

Voltage	300.0 V	Storage Temperature	-40° - 60° C
---------	---------	---------------------	--------------
