




Wiremold
8801S-FC Omnibox Series Fire Classified 1-Gang Floor Box
Part No. 8801S-FC

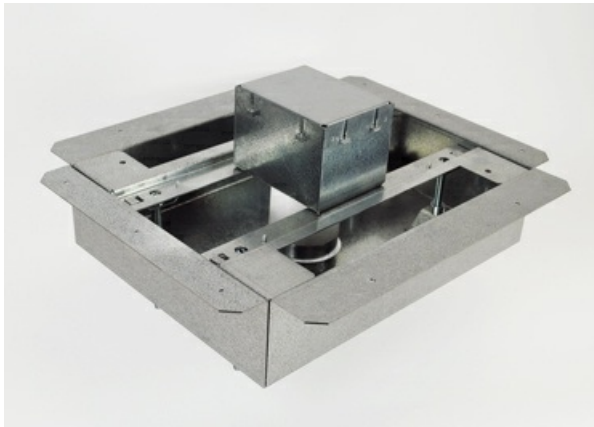

1-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 5" (127mm) maximum. Use in normal weight concrete 4 1/2" (114mm) minimum pour over deck. One 1 1/4" (32mm) conduit feed opening. Box Capacity 53 cubic inches. This floor box preserves the 2-hour fire rating of floors in which it has been installed.

Features & Benefits

1-Gang Fire Classified Steel Floor Box.

Adjustment range over deck of 2" (51mm) minimum to 5" (127mm) maximum.

Use in normal weight concrete 4 1/2" (114mm) minimum pour over deck. One 1 1/4" (32mm) conduit feed opening. Box Capacity 53 cubic inches.

This floor box preserves the 2-hour fire rating of floors in which it has been installed.

Specifications

General Info

Product Line	Wiremold	UPC Number	786776183146
Country Of Origin	United States	Construction	Assembled
Cover Style	Flush	Application Sector	Commercial
Standard	cULus Listed Metallic Outlet Boxes: File E2961 Guide QCIT Meets Article 314.27(C) of NEC.	Warranty Type	1-Year from Installation or 2-Years from Day of Sale
Type	Floor Box		

Dimensions

Product Weight US	24.0 lb	Cubic Capacity	53 in ³
Knockout Size	1 in		

Listing Agencies / 3rd Party Agencies

cULus ListingNumber	E2961	cULus Listed	Yes
---------------------	-------	--------------	-----

Additional Information

RoHS Compliant Yes

Technical Information

Floor Type	Concrete	Service Capacity	Single
Minimum Floor Depth	2 in	Fire Rating	2 hr
Box Capacity	1 Gang	Cable Entry	conduit Feed Channels
Box Type	Fire Classified	Number of Outlets	2
Depth Behind Device Plates	2.75 in		