




Wiremold  
8802S-FC12 Omnibox Series Fire Classified 2-Gang Floor Box  
Part No. 8802S-FC12

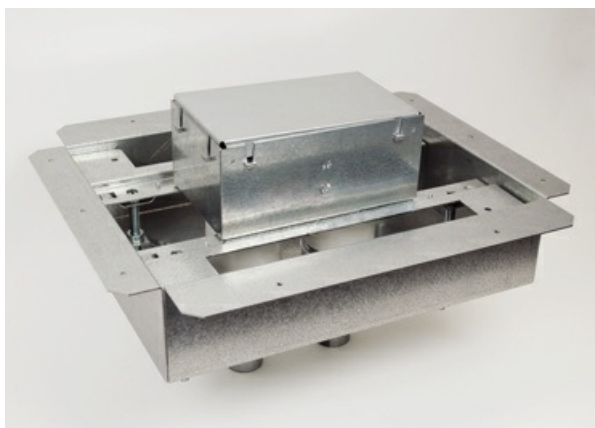

2-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 6-1/2" (165mm) maximum. One 1 1/4" (32mm) and One 2" (51mm) conduit feed openings. Box Capacity - 58.5 cubic inches each gang. This floor box preserves up to a 3-hour fire rating of floors in which it has been installed.

## Features & Benefits

2-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 6-1/2" (165mm) maximum. One 1 1/4" (32mm) and One 2" (51mm) conduit feed openings. Box Capacity - 58.5 cubic inches each gang.

This floor box preserves up to a 3-hour fire rating of floors in which it has been installed.

## Specifications

### General Info

Product Line	Wiremold	UPC Number	786776184198
Country Of Origin	United States	Construction	Assembled
Cover Style	Flush	Number of Knockouts	1
Application Sector	Commercial	Standard	cULus Listed Metallic Outlet Boxes: File E2961 Guide QCIT Meets Article 314.27(C) of NEC.
Warranty Type	1-Year from Installation or 2-Years from Day of Sale	Type	Floor Box

### Dimensions

Product Width US	11.375 in	Product Weight US	23.0 lb
------------------	-----------	-------------------	---------

Product Depth US	3.5 in	Product Length US	20.0 in
Cubic Capacity	58.5 in³	Knockout Size	1 in
Listing Agencies / 3rd Party Agencies			
cULus ListingNumber	E2961	cULus Listed	Yes
Trade Programs			
USMCA	Yes		
Additional Information			
RoHS Compliant	Yes		
Technical Information			
Floor Type	Concrete	Service Capacity	Dual
Minimum Floor Depth	2 in	Fire Rating	3 hr
Box Capacity	2 Gangs	Cable Entry	CONDUIT
Box Type	Fire Classified	Depth Behind Device Plates	2.75 in