




radiant Collection
radiant® 20A 125V Tamper-Resistant Outlet, White
Part No. 885TR20SW

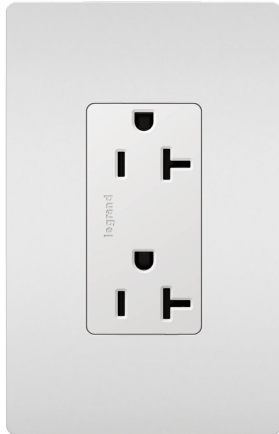

Take a step up from standard with Legrand's 20A/125V radiant® Tamper Resistant, Self-Grounding, Duplex Outlet. This tamper-resistant duplex 20-amp outlet installs easily for the basic power every home needs, while elevating your space with the sleek, clean lines of radiant® for a sophisticated look. To help prevent improper insertion of foreign objects and comply with NEC Article 406.12, these receptacles feature black "invisi-shutters" that disappear for an invisible effect preferred by end users. This outlet also includes a self-grounding feature that makes it ideal for residential and multi-dwelling applications. Pair with a screwless radiant® Wall Plate and other designer switches and outlets from the radiant® Collection for a cohesive design throughout the home. Made exclusively for use with screwless Wall Plates from the radiant® Collection, sold separately.

Features & Benefits

Ideal for Residential Applications & Multi-Dwelling units where 20A devices are required

Meets National Electric Code Tamper-Resistant requirements per Article 406.12

Black "Invisi-Shutters" disappear for an invisible effect

Side Wire Only accepts #12-#14 AWG

Auto-Ground Clip assures a positive ground connection is made

Pair with a screwless radiant wall plate and coordinate with other designer switches & outlets from the collection for a cohesive look.

Specifications

General Info

| | | | |
|--------------------|--|-----------------------|--|
| Product Line | Pass & Seymour | Color | White |
| Finish | Glossy | Country Of Origin | China |
| Receptacle Type | Straight Blade | Number of Receptacles | 2 |
| Construction | Injection molded plastic | Features | Self-Grounding |
| Outlet Type | Indoor, Self-Grounding, Tamper-Resistant | Package Quantity | 1 |
| Application Sector | Residential | Standard | RoHS, UL (UL498, E140596), cULus (E140596), CSA (C22.2 No. 42), NEMA (WD-1 & WD-6) |

| | | | |
|---------------|-------------------------|------|---------------------------|
| Warranty Type | 1-Year Limited Warranty | Type | Decorator, Duplex, Outlet |
|---------------|-------------------------|------|---------------------------|

Dimensions

| | | | |
|------------------|---------|-------------------|----------|
| Product Width US | 1.42 in | Product Weight US | 0.122 lb |
| Product Depth US | 1.03 in | Product Height US | 4.2 in |

Listing Agencies / 3rd Party Agencies

| | | | |
|--------------|-----|---------------------|--------------|
| CSA Listed | Yes | cULus ListingNumber | UL498 |
| cULus Listed | Yes | CSA File Number | C22.2 No. 42 |

Additional Information

| | |
|-----------------|-----|
| RoHS Conformant | Yes |
|-----------------|-----|

Technical Information

| | | | |
|-------------------------|-------------|--------------------------|---|
| Is Tamper-Resistant | Yes | Connection | Side Wire Only |
| Number of Wires | 3 | Amperage | 20 A |
| Number of Poles | Double Pole | Wire Size | 14 - 12 AWG |
| Is Weather Resistant | No | Indoor/Outdoor | Indoor |
| NEMA Configuration Code | NEMA 5-20 | Mounting Type | Screwless |
| Voltage | 125.0 V | Environmental Conditions | 98% (relative humidity, non-condensing) |
