




Cablofil  
Vtrough Center Hanger 300 BLACK  
Part No. 960768

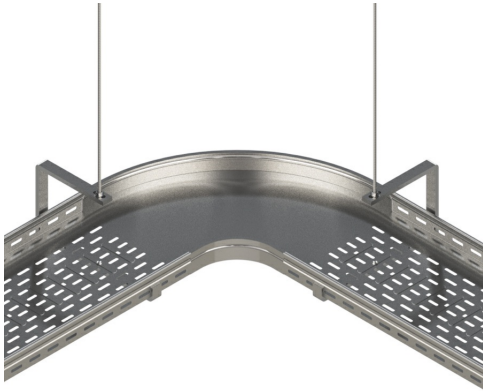

Center Hanging Fiber Trough tray makes adding cables easy with the new ESO P31. The open side allows greater access to cable pathways up to 12" wide and makes covers easier to remove and replace. Designed for medium duty loads, the ESO P31 accepts 3/8" threaded rod and attaches to the tray with EZBN1/4 bolts. ESO P31 available in EZ (Electrozinc) and GC (Hot Dipped Galvanized) to match your application environment.

## Features & Benefits

Open side allows cables to added to pathway easily

Use with 3/8" threaded rod

Packaged in sets of 6 and 10

Works with Fiber Trough or V-Trough Tray up to 12" wide

Steel construction is available in two finishes.

## Specifications

### General Info

Product Line	Cablofil	Finish	Painted
UPC Number	800388471856	Country Of Origin	Italy

### Dimensions

Product Width US	12.75 in	Product Weight US	2.88 lb
Product Volume US	0.048 cu ft	Product Depth US	6.5 in
Product Height US	1.0 in		

### Trade Programs

BAA	Yes
-----	-----