




adorne Collection
adorne® 0-10V Touch Dimmer, Magnesium, with Microban®
Part No. ADTH4FBL3PM4

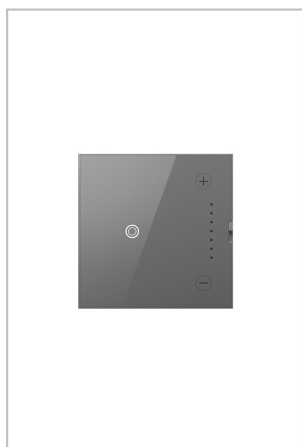

Perfect anywhere you'd like to turn lights on and off with the simplest touch, while also enjoying the ability to dim. Featuring a translucent glass-like face, this modern dimmer lets you control your lights by simply pressing a finger to the center circle to turn lights on/off, or use the + or - on the side to dim. Use the dimmer switch on its own to control a 0-10V light or fixture from a single location, or pair with a 3-way switch to control a single light source from two locations. Pair with the matching Touch Switch for a consistent control-style throughout a room, or your entire house.

This dimmer* features enduring Microban® antimicrobial technology that works to reduce the growth of bacteria, around the clock, for the lifespan of the product.

* Existing inventory of switches, dimmers and plastic wall plates from the adorne® Collection at some partner locations may not yet include Microban® protection. To confirm that a specific Legrand product is protected with Microban®, check that the exterior of the product packaging includes a green dot or a "Protected with Microban" label.

Made exclusively for use with screwless Wall Plates from the adorne® Collection, sold separately.

No antimicrobial efficacy claims are being made or are valid with respect to products sold in Canada.

Features & Benefits

Helps fight the growth of stain and odor-causing bacteria through the invisible and continuous product protection of Microban® antimicrobial technology

Installs in 15 minutes or less, fitting into an existing electrical box. No new wiring required for typical installation.

Usable in both single-pole and 3-way applications.

For complete installation, device must be paired with an adorne® screwless Wall Plate (not included). Available in a range of contemporary colors and stunning finishes.

For use with dimmable 0-10V bulbs or fixtures. Features intuitive touch control for switching on/off and adjusting light levels.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

Specifications

General Info

Product Line	Pass & Seymour	Color	Magnesium
Finish	Metallic	UPC Number	785007055955

Country Of Origin	China	Features	Antimicrobial Protection, Locator Light, Low-End Trim (Dim Range)
Switch Type	Digital, Single Pole 3-Way, Touch	Number of Switches	1
Device Front Face Size	Full-Size	Device Backbody Size	Plus-Size
Application Sector	Commercial, Hospitality, Residential	Standard	cULus
Warranty Type	Limited Lifetime Warranty		
Dimensions			
Product Width US	1.77 in	Product Depth US	1.62 in
Product Height US	1.77 in		
Technical Information			
Load Rating	120V 10A (Fluorescent), 120V 10A (LED), 277V 5A (Fluorescent), 277V 5A (LED)	Dimming Compatibility	0-10 V
Frequency Rating	60 Hz	Number of Gangs	1
Bulb Compatibility	Fluorescent, LED	Number of Poles	Single Pole 3-Way
Wire Size	#14 - #10 AWG	Trim/Adjustment Level	Button
Requires Neutral Wire	Yes	Indoor/Outdoor	Indoor
Mounting Type	Wall Box	Wire Connection Type	Flying Leads (0-10V), Screw Terminals
Voltage	120/277 VAC		