




adorne Collection
adorne® 15W USB Outlet, Type A/C, Magnesium
Part No. ARUSB2AC6M4

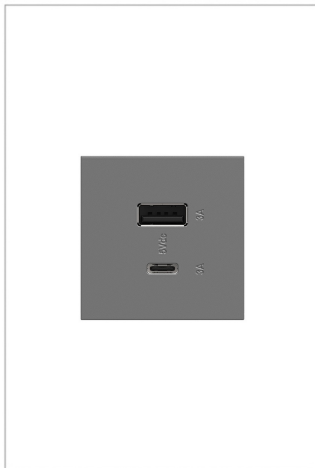

Charge phones, tablets and more up to 40% faster, with USB Outlets from the adorne® Collection. Made to deliver a leading 6 amps of power, it features two built-in USB connections, including one to fit USB Type-C devices, and provides a fast, future-proof solution for convenient in-wall charging without an adapter. Easily replacing traditional outlets in as little as ten minutes, this USB Outlet transforms your space with modern functionality and the unique, contemporary aesthetic of adorne. Made exclusively for use with screwless Wall Plates from the adorne® Collection, sold separately.

Features & Benefits

For complete installation, device must be paired with an adorne® screwless Wall Plate (not included). Available in a range of contemporary colors and stunning finishes.

Features an industry-leading 6.0A of power, as well as Smart Chip technology, to maximize charging speed for each USB connection.

Replaces a traditional outlet easily, in as little as 10 minutes.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

Provides fast and convenient built-in charging, without sacrificing plugs or requiring a bulky adapter.

Includes connections for both traditional USB Type-A and the newer USB Type-C, to accommodate all mobile devices.

Legrand USB Outlets are manufactured through high-quality design, sourcing and production, and backed by a Lifetime Warranty.

Specifications

General Info

Product Line	Pass & Seymour	Color	Magnesium
Finish	Frosted	UPC Number	785007262377
Country Of Origin	China	Features	USB-A Charging, USB-C Charging
Outlet Type	Tamper-Resistant, USB-Charging	Application Sector	Commercial, Multi-Dwelling Unit, Residential
Wall Plate Included	No	Standard	yes
Warranty Type	Limited Lifetime Warranty		

Dimensions

Product Width US	1.77 in	Product Depth US	1.7 in
Product Height US	2.65 in		

Technical Information

Connection Location	Back Only	USB Wattage	15 W
USB Amperage	6 A	Connection	USB Type A/C
Number of USBs	2	Number of Wires	3
Number of Gangs	1	Number of Poles	Double Pole
Wire Size	14 - 12 AWG	Indoor/Outdoor	Indoor
Mounting Type	Box	Wire Connection Type	Internal Pressure Plates
Voltage	125.0 V	Environmental Conditions	95% (relative humidity, non-condensing)
