




adorne Collection
adorne® 30W Dual USB Outlet Module, Type C, Graphite
Part No. ARUSB30PDG4

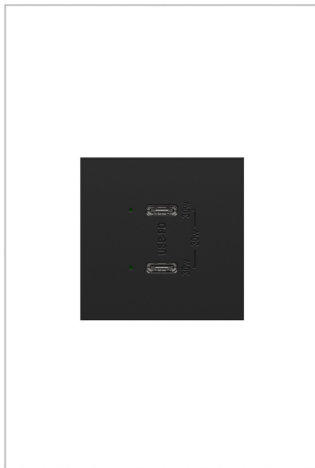

Charge phones, tablets and more up to 40% faster, with USB Outlets from the adorne® Collection. This solution adds advanced Power Delivery to provide fast in-wall charging without an adapter. Easily replacing traditional outlets in as little as ten minutes, this USB Outlet transforms your space with modern functionality and the unique, contemporary aesthetic of adorne. Made exclusively for use with screwless Wall Plates from the adorne® Collection, sold separately.

Features & Benefits

For complete installation, device must be paired with an adorne® screwless Wall Plate(not included). Available in a range of contemporary colors and stunning finishes.

Charges the latest devices up to 2X faster with 6.0 amps and 30W of power courtesy of advanced Power Delivery.

Built for intelligent charging, the outlet detects and delivers the precise amount of power needed to maximize charging speeds.

Provides fast and convenient built-in charging through two future-proof USB Type-C ports, accommodating new and upcoming devices without an adapter.

Helpful indicator light lets you see charging status at a glance. Light glows yellow while charging is in progress, and shows green once the device battery is sufficiently charged.

Includes multiple layers of overcurrent protection, ensuring the outlet and your favorite devices can charge at optimal levels without risk of damage.

Legrand USB Outlets are manufactured through high-quality design, sourcing and production, and backed by a Lifetime Warranty.

Replaces a traditional outlet easily, in as little as 10 minutes, with features like scalloped cover design and posted side-wire terminal screws for faster installation.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

Specifications

General Info

Product Line	Pass & Seymour	Color	Graphite
UPC Number	785007378061	Country Of Origin	China
Features	USB-C Charging	Device Front Face Size	Full-Size
Device Backbody Size	Plus-Size	Outlet Type	Tamper-Resistant, USB-Charging
Application Sector	Commercial, Residential	Warranty Type	Limited Lifetime Warranty

Type	Tamper-Resistant, USB		
Dimensions			
Product Width US	1.77 in	Product Depth US	1.7 in
Product Height US	2.65 in		
Additional Information			
RoHS Compliant	Yes		
Technical Information			
USB Amperage	6 A	Connection	USB Type C/C
Number of USBs	2	Output Current	6A
USB Power Output	30 W	Amperage	20 A
Current Rating	20 A	Indoor/Outdoor	Indoor
Environmental Conditions	95% (relative humidity, non-condensing)		