




adorne Collection
adorne® 277V Paddle Switch, Graphite, with Microban®
Part No. ASPD1532G277

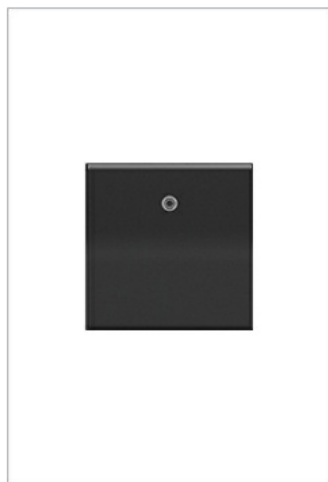

A modern twist on classic up-and-down light switch control, the Paddle Switch lets you turn lights on and off with ease and style. Use this 277V switch on its own to control a light or fixture from a single location, or pair with a second switch to control a single light source from two locations.

This switch* features enduring Microban® antimicrobial technology that works to reduce the growth of bacteria, around the clock, for the lifespan of the product.

* Existing inventory of switches, dimmers and plastic wall plates from the adorne® Collection at some partner locations may not yet include Microban® protection. To confirm that a specific Legrand product is protected with Microban®, check that the exterior of the product packaging includes a green dot or a "Protected with Microban" label.

Made exclusively for use with screwless Wall Plates from the adorne® Collection, sold separately.

No antimicrobial efficacy claims are being made or are valid with respect to products sold in Canada.

Features & Benefits

Helps fight the growth of stain and odor-causing bacteria through the invisible and continuous product protection of Microban® antimicrobial technology

Installs in 15 minutes or less, fitting into an existing electrical box. No new wiring required for typical installation.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

For complete installation, device must be paired with an adorne® screwless Wall Plate (not included). Available in a range of contemporary colors and stunning finishes.

Usable in both single-pole and 3-way applications.

Specifications

General Info

Product Line	Pass & Seymour	Color	Graphite
Finish	Metallic	UPC Number	785007234404
Country Of Origin	China	Features	Antimicrobial Protection
Switch Type	Paddle	Number of Switches	1

Application Sector	Hospitality, Residential	Wall Plate Included	No
Warranty Type	Limited Lifetime Warranty	Type	Switch
Dimensions			
Product Width US	1.77 in	Product Depth US	1.5 in
Product Height US	1.77 in		
Technical Information			
Connection Location	Back Only	Terminal Accommodation	#14 AWG - #12 AWG
Number of Gangs	1	Throw Type	Single Throw
Amperage	15 A	Number of Poles	Single Pole 3-Way
Requires Neutral Wire	Yes	Indoor/Outdoor	Indoor
Mounting Type	Box	Supply Voltage	277 VAC
Wire Connection Type	Internal Pressure Plates	Voltage	277.0 V
Load Type	CFL, Fluorescent, Halogen, Incandescent, LED, Universal, Xenon	Environmental Conditions	10 to 90% (relative humidity, non-condensing)