




adorne Collection  
adorne® sofTap® Switch, Magnesium, with Microban®  
Part No. ASTP1532M4

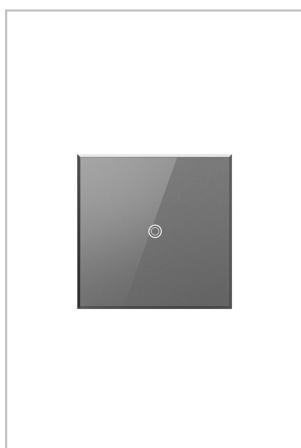

Turn lights on/off with just a soft tap of a finger, thanks to the inventive micro-movement technology of this beautifully modern designer light switch.

This switch\* features enduring Microban® antimicrobial technology that works to reduce the growth of bacteria, around the clock, for the lifespan of the product.

\* Existing inventory of switches, dimmers and plastic wall plates from the adorne® Collection at some partner locations may not yet include Microban® protection. To confirm that a specific Legrand product is protected with Microban®, check that the exterior of the product packaging includes a green dot or a "Protected with Microban" label.

Made exclusively for use with screwless Wall Plates from the adorne® Collection, sold separately.

No antimicrobial efficacy claims are being made or are valid with respect to products sold in Canada.

## Features & Benefits

Helps fight the growth of stain and odor-causing bacteria through the invisible and continuous product protection of Microban® antimicrobial technology

Installs in 15 minutes or less, fitting into an existing electrical box. No new wiring required for typical installation.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

For complete installation, device must be paired with an adorne® screwless Wall Plate (not included). Available in a range of contemporary colors and stunning finishes.

Features innovative micro-movement control that turns lights on and off with a lighter push action. Usable in both single-pole and 3-way applications.

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Magnesium
Finish	Frosted	UPC Number	785007022902
Country Of Origin	China	Features	Antimicrobial Protection
Switch Type	sofTap	Number of Switches	1
Device Front Face Size	Full-Size	Device Backbody Size	Plus-Size

Application Sector	Residential	Standard	cULus
Warranty Type	Limited Lifetime Warranty		
Dimensions			
Product Width US	1.77 in	Product Depth US	1.63 in
Product Height US	2.66 in		
Technical Information			
Connection	Screw Terminals	Number of Gangs	1
Amperage	15 A	Number of Poles	3-Way, Single Pole
Wire Size	#14 - #10 AWG	Mounting Type	Box
Connection Type	Internal Pressure Plates		