




adorne Collection
adorne® Motion Sensor Switch, Manual On/Auto Off, Graphite, with Microban®
Part No. ASVS12G4

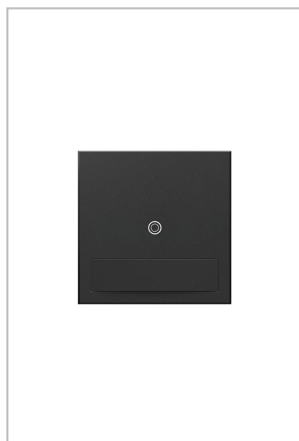

From bedrooms to basements, this motion sensor switch is perfect for anywhere you might want to worry (or waste electricity) less. A conveniently modern light switch, it features combination control that allows you to manually turn lights on when entering a room, and then automatically turns the lights off for you when you leave. Use this device on its own to control a light or fixture from a single location one location, or combine with additional switches for controlling a single light source from multiple locations in 3 or 4-way applications.

This switch* features enduring Microban® antimicrobial technology that works to reduce the growth of bacteria, around the clock, for the lifespan of the product.

* Existing inventory of switches, dimmers and plastic wall plates from the adorne® Collection at some partner locations may not yet include Microban® protection. To confirm that a specific Legrand product is protected with Microban®, check that the exterior of the product packaging includes a green dot or a "Protected with Microban" label.

Made exclusively for use with screwless Wall Plates from the adorne® Collection, sold separately.

No antimicrobial efficacy claims are being made or are valid with respect to products sold in Canada.

Features & Benefits

Helps fight the growth of stain and odor-causing bacteria through the invisible and continuous product protection of Microban® antimicrobial technology

Installs in 15 minutes or less, fitting into an existing electrical box. No new wiring required for typical installation.

Usable in single-pole or 3-way applications. Must be paired with another SensaSwitch or SensaDimmer for 3-way control.

For complete installation, device must be paired with an adorne® screwless Wall Plate (not included). Available in a range of contemporary colors and stunning finishes.

Uses SensaSwitch technology to automatically turn lights off after you leave. (Auto shut-off can be set from 5 to 30 minutes after vacancy.)

More color options available to fit any style, including finishes to match current hardware and lighting trends.

Specifications

General Info

Product Line	Pass & Seymour	Color	Graphite
Finish	Metallic	UPC Number	785007234800
Country Of Origin	China	Features	Adjustable Time Delay, Antimicrobial Protection, Light Level Sensor, Motion Sensor

Switch Type	Motion Sensor, softTap	Number of Switches	1
Installation Location	Wall Box	Application Sector	Hospitality, Light Commercial, Multi-Dwelling Unit, Residential
Warranty Type	Limited Lifetime Warranty		
Dimensions			
Product Width US	1.77 in	Product Depth US	1.85 in
Product Height US	2.66 in		
Technical Information			
Load Rating	120V 5A (ELV), 120V 5A 600W (CFL), 120V 5A 600W (LED), 120V 600VA (Fluorescent), 120V 600VA (MLV), 120V 600W (Halogen), 120V 600W (Incandescent)	Horsepower Rating	1/6 HP @ 120 VAC
Sensor Coverage Pattern	180 °	Sensor Type	Vacancy
Sensor Technology	Passive Infrared (PIR)	Timer Duration	15 Minutes, 30 Seconds-30 Minutes
Number of Poles	3 Way, Single Pole	Wire Size	#14 - #10 AWG
Input Voltage	120 VAC	Requires Neutral Wire	No
Line Frequency	60 Hz	Indoor/Outdoor	Indoor
Sensor Coverage	600 sq ft	Mounting Type	Wall Box
On Function	Manual On	Operating Humidity	0-95% RH (Non-Condensing)
Sensing Range	Major Motion 35 ft, Minor Motion 20 ft	Wire Connection Type	Screw Terminals
Voltage	120 VAC	Connection Type	Internal Pressure Plates
Load Type	CFL, Fan Motor, Halogen, Incandescent:Fluorescent, LED		