




Wiremold  
CRFB Series Surface Style Solid Cover Assembly  
Part No. CRFBBTCBK

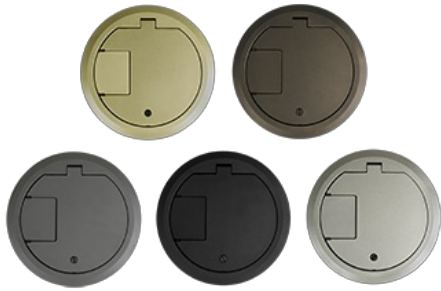

Available in die cast aluminum with a painted black (BK), brass (BS), nickel (NK), bronze (BZ) or gray (GY) finish. No cutouts are provided for floor coverings. Add suffix "TR" to the end of the part number to indicate tamper-resistant cover assembly.

## Features & Benefits

Available in die cast aluminum with a painted black (BK), brass (BS), nickel (NK), bronze (BZ) or gray (GY) finish. No cutouts are provided for floor coverings. Add suffix "TR" to the end of the part number to indicate tamper-resistant cover assembly.

## Specifications

### General Info

Product Line	Wiremold	Finish	Painted
UPC Number	786564076872	Country Of Origin	China
Construction	Assembled	Cover Style	Surface
Cover Material	Die-Cast Aluminum	Application Sector	Commercial
Standard	UL Listed Classified Raised Floor Box: File E2961 Guide QCIT, UL Listed Classified Raised Floor Box (prewired): File E51105 Guide QQVX Meets Article 314 of NEC. Meets Article 12-2500 of CEC.	Warranty Type	1-Year from Installation or 2-Years from Day of Sale
Type	Cover		

### Dimensions

Product Width US	9.29 in	Product Weight US	2.5 lb
------------------	---------	-------------------	--------

### Listing Agencies / 3rd Party Agencies

cULus ListingNumber	E2961	cULus Listed	Yes
---------------------	-------	--------------	-----

Additional Information

RoHS Compliant	Yes	Product Environmental Profile	Yes
----------------	-----	-------------------------------	-----

Technical Information

Floor Type	Carpet, Tile	Cable Entry	Through Floor
------------	--------------	-------------	---------------