




Wiremold
Plug-In Outlet Center Unit / Plug-In Outlet Center Unit / Steel/120V/15A/40 long/6 O/L /6' cord
Part No. G20-C2

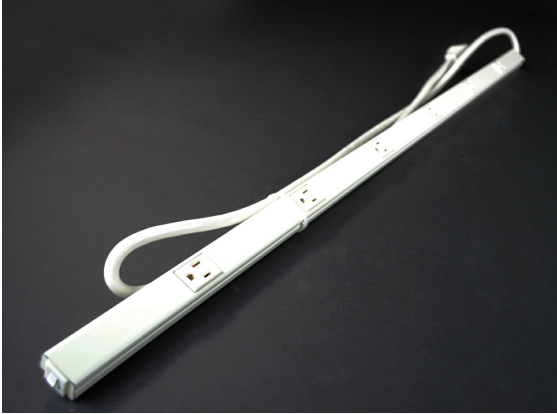

Six outlets, steel housing with ivory finish. 6' (1.8m) cord. Length 40" (1m). Receptacle center-to-center 6" (152mm).

Features & Benefits

Six outlets, steel housing with ivory finish. 6' (1.8m) cord. Length 40" (1m). Receptacle center-to-center 6" (152mm).

Specifications

General Info

Product Line	Wiremold	UPC Number	786776090451
Country Of Origin	United States	Number of Receptacles	6

Application Sector	Commercial	Standard	cULus Listed Base & Blank Cover: File E4376 Guide RJBT. Multioutlet Assemblies: File E15191 Guide PVGT. Fittings: File E41751 Guide RJPR. Base & Blank Cover & Plugmold Series w/Snapicoil Haarness: Meets Article 386 of NEC. Meets Section 12-3032 of CEC. cULus Listed Raceway: File E4376 Guide RJBT. Fittings: File E41751 Guide RJPR. Base & Black Cover: Meets Article 386 of NEC. Meets Section 12-600 of CEC.
--------------------	------------	----------	--

Type	Plugmold
------	----------

Listing Agencies / 3rd Party Agencies

CSA Listed	Yes	CSA File Number	LR350
------------	-----	-----------------	-------

Buy American Act Compliance

NAFTA	Yes
-------	-----

Additional Information

RoHS Conformant

Yes

Product Environmental Profile Yes

Technical Information

Amperage

15 A

Enclosure Type

Steel

Voltage

125.0 V

Environmental Conditions

Dry interior locations
