




Ortronics  
**Infinium HDFP Adapter Panel, 4 ST Duplex, Green**  
Part No. HDFP-STD08CC

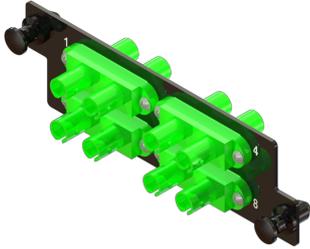

Infinium HDFP Adapter Panels offer pass through connections and front-loading access. The compact design optimizes space and features fiber port labeling for easier identification. Compatible with Infinium HD-E Rack Mount Fiber Enclosure with M4 Drawer Face.

## Features & Benefits

- Compact high density design: Optimized space utilization
- Plunger/grommet fasteners: Quick and easy insertion and removal
- Front loading: Easy access to connections
- Fiber port labeling: Provides fiber port identification for easier administration
- Engineered polymer adapter panel: Rugged, cost-effective design

## Specifications

### General Info

Product Line	Ortronics	Color	Green
UPC Number	662875029069	Country Of Origin	Mexico
Features	Fiber Port Labeling	Included	Cover
Application Sector	Commercial, Data Center	Warranty Type	5-Year
Type	Adapter Panel		

### Dimensions

Product Width US	4.19 in	Product Depth US	0.9 in
Product Height US	1.24 in		

### Technical Information

---

Fiber Optic Cable Type	OS2	Operating Temperature Min	-10 °C
Compatibility	HDFP, LM4, M4	Number of Ports	8
Simplex/Duplex	Duplex	Operating Temperature Max	60 °C
Single/Multimode	Single-Mode	Number of Fibers	8
Connector 2	LC Female	Connector 1	LC Female
Operating Temperature	-10°-60°C	Durability	500 matings
Operating Humidity	0-80% RH (Non-Condensing)	Storage Temperature	-40° - 75° C

---