




radiant Collection  
radiant® Fan Speed Control De-Hummer, Single Pole/3-Way, Tri-Color  
Part No. HDH163PMMTC

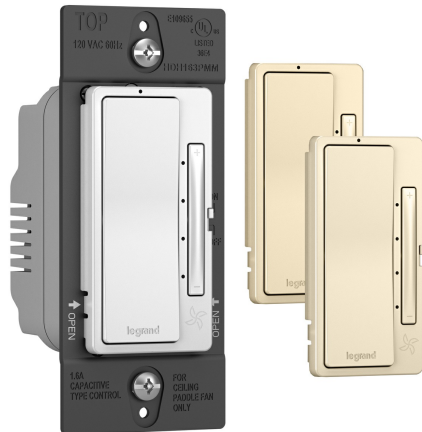

Specially designed capacitive circuitry de-hummer feature virtually eliminates fan motor hum for quiet fan speed control. Made exclusively for use with screwless Wall Plates from the radiant® Collection, sold separately.

## Features & Benefits

Multi-location dimming compatible with 3-way wiring for simple installation.

Designed to virtually eliminate the motor's hum for quieter use.

Constant memory returns lights to previous level after a power failure.

Part of the radiant® collection.

Complete the look with a sleek, screwless radiant® Wall Plate, and coordinate with other designer switches and outlets available from the radiant® Collection.

## Specifications

### General Info

Product Line	Pass & Seymour	Color	White
Finish	Matte	UPC Number	785007039696
Country Of Origin	China	Features	Fan Control, Preset
Switch Type	Paddle	Number of Switches	1
Application Sector	Residential	Warranty Type	1-Year Limited Warranty
Type	Switch		

### Dimensions

Product Width US	1.75 in	Product Depth US	1.25 in
Product Height US	4.25 in		

---

Listing Agencies / 3rd Party Agencies

---

cULus Listed	Yes
--------------	-----

---

Technical Information

---

Number of Gangs	1	Amperage	15 A
Number of Poles	3-Way, Single Pole	Wire Size	#14 - #10 AWG
Mounting Type	Box	Voltage	120.0 V

---