




Ortronics  
**Mighty Mo® 20 Adjustable 4-Post Racks**  
Part No. MM20730ADJ38-B

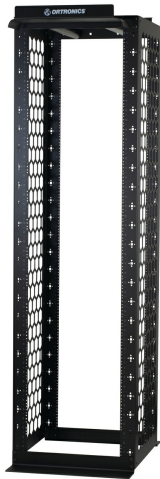

Mighty Mo 20 4-post racks provide greater flexibility and optimum efficiency in any data center. The adjustable rack allows all 4 mounting rails to be adjusted even after the rack has been fastened to the floor. Front and rear waterfalls allow for equipment patching and server patching. All styles of Mighty Mo 20 vertical managers can be mounted front or rear and airflow baffles can be mounted to manage the airflow of side breathing equipment.. Note: Static capacity 2,000 lbs. Assembly required. Replace the "X" tail code with "B" for black or "W" for white.

## Features & Benefits

Large selection of Channel and 4-Post racks	All 4 mounting rails to be adjusted even after the rack has been fastened to the floor
Front and rear waterfalls allow for equipment patching and server patching	Static capacity 2,000 lbs
Threaded hole and square hole punch available on all channel and 4 post racks	Deeper waterfall for increased cable capacity
Rack includes two packages of hook and loop D-style straps and 50 #12-24 cage nuts and screws, do not have to purchase as separate items; money saving	

## Specifications

### General Info

Product Line	Ortronics	Color	Black
UPC Number	662875949008	Country Of Origin	United States
Application Sector	Commercial	Standard	UL 2416
Type	Rack		

### Dimensions

Product Width US	23.75 in	Product Weight US	54.35 lb
Product Depth US	40.0 in	Product Height US	86.0 in

### Additional Information

RoHS Conformant	Yes
-----------------	-----

Technical Information			
-----------------------	--	--	--

Rack Units	45	Static Load Capacity	2000 lb
------------	----	----------------------	---------