




Cablofil
Discontinued - VC-A639-0010-18 G 6"H TROUGH 10'L 18"W
Part No. VC-A639-0010-18

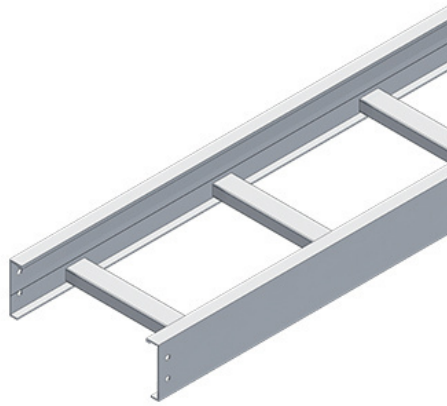

Choose from an extensive selection of metallic ladder tray with a variety of rung and bottom styles to choose from. Rail heights range from 4" to 7" and width sizes are available up to 36".

Features & Benefits

Material: Commercial Quality Steel / ASTM A-1008 / A-1011

Finish: Ho-dip Galvanized after Fabrication / ASTM A-123

Bottom: Ldr: 1" wide + rung SC: Solid Corrugated VC: Vented Corrugated

Construction: Welded

Tray Design: Tray construction and markings are per the latest edition of NEMA Standards Publication VE1, CSA C22.2 No. 126

Tray Grounding Capability: Classified as an equipment grounding conductor per NEC 392.60

Specifications

General Info

Product Line	Cablofil	Finish	Hot Dipped Galvanized after Fabrication
UPC Number	800388262843	Country Of Origin	Mexico
Material	Carbon Steel	Bottom Type	Vented Corrugated
Application Sector	Commercial, Industrial	Type	Straight Sections

Dimensions

Product Width US	18.0 in	Product Weight US	50.951 lb
Product Volume US	7.5 cu ft	Product Depth US	120.0 in
Product Height US	6.0 in	Tray Height	6 in

Trade Programs

BAA	Yes
-----	-----

Technical Information

NEMA Load Class	12C
-----------------	-----
