




Cablofil  
09-7400-0010-12 FG 4"H Fiberglass Ladder 10'L 12"W  
Part No. P027688

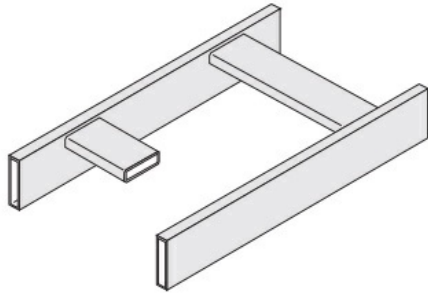

For extremely corrosive applications we offer a full line of straight sections, fittings, covers and mounting accessories in polyester and vinylester fiberglass. Rail heights are available in 4" and 6" and widths are available up to 36".

## Features & Benefits

Material: Pultruded from Glass Fiber Reinforced Fire Retardant Polyester Resin

Finish: Plain

Bottom: Ldr = 1" square tube rung

Tray Design: Tray construction and markings

Connectors: Supplied in pairs with hardware

## Specifications

### General Info

Product Line	Cablofil	Finish	Other
UPC Number	800388511620	Country Of Origin	United States
Bottom Type	Ladder	Application Sector	Commercial, Industrial
Type	Straight Sections		

### Dimensions

Product Width US	12.0 in	Product Weight US	20.66 lb
Product Volume US	3.333 cu ft	Product Depth US	120.0 in
Product Height US	4.0 in	Rung Spacing	9 in

## Trade Programs

BAA	Yes
-----	-----

Technical Information

NEMA Load Class	12C
-----------------	-----