




**Pass and Seymour
Range and Dryer Box**
Part No. P242RRD

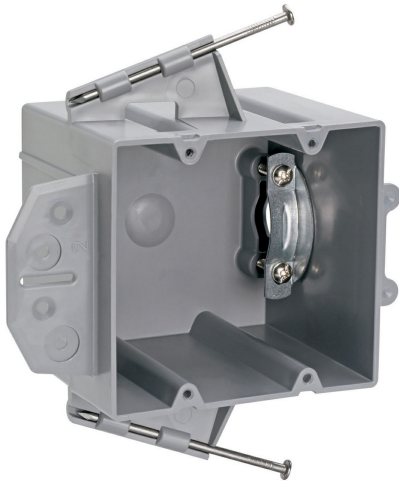

Range and Dryer Box with captive Mounting Nails on Each End. 1/2-inch offset for wood or steel stud mounting with metal cable clamp. 12 pack.

Features & Benefits

Auto/Clamps on each end eliminate the need for separate cable clamps.

Easy installation, rectangular cutout.

Location ribs enable the installer to quickly and accurately maintain a 1/2 inch offset.

Constructed of impact-resistant thermoplastic.

Specifications

General Info

Product Line	Pass & Seymour	Color	Gray
UPC Number	785007306156	Country Of Origin	United States
Material	Thermoplastic	Features	Integral Clamp
Installation Location	Wall	Application Sector	Commercial, Residential
Standard	UL listed	Warranty Type	1-Year Limited Warranty
Type	Range & dryer Box		

Dimensions

Product Width US	4.0 in	Product Weight US	0.43 lb
Product Volume US	42.0 cu in	Product Depth US	4.0 in
Product Height US	3.75 in	Product Length US	3.75 in

Cubic Capacity	42 in ³
----------------	--------------------

Additional Information

RoHS Compliant	Yes
----------------	-----

Technical Information

Number of Gangs	1	Indoor/Outdoor	Indoor
-----------------	---	----------------	--------

Cable Entry	Side	Box Shape	Rectangular
-------------	------	-----------	-------------

Mounting Type	Nail On
---------------	---------
