




Cablofil
LD-4A-90VI12-06 AL 4H 90° IVR 12R 06W (TRA)
Part No. P302831

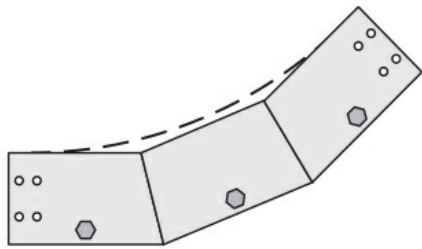

The aluminum I-beam design of ITray is perfect for industrial installations with large diameter cables in long span situations, minimizing total tray width and creating a smooth transition between straight sections and fittings. A structural offset in the sidewall creates strong, mid-span splices that need fewer supports. Each splice snaps in place and stays without holding. Additionally, only four bolts are needed for each splice reducing hardware needs by 50%. These features allow Itray to be installed up to 30% faster than standard tray.

Features & Benefits

Includes splices and hardware

Specifications

General Info

| | | | |
|--------------|-----------------|--------------------|------------------------|
| Product Line | Cablofil | Finish | Aluminum |
| UPC Number | 800388086975 | Country Of Origin | Mexico |
| Bottom Type | Ladder | Application Sector | Commercial, Industrial |
| Type | Vertical Elbows | | |

Dimensions

| | | | |
|-------------------|-------------|-------------------|----------|
| Product Width US | 7.5 in | Product Weight US | 6.356 lb |
| Product Volume US | 1.567 cu ft | Product Depth US | 19.0 in |
| Product Height US | 19.0 in | Radius | 12 in |

Trade Programs

| | |
|-----|-----|
| BAA | Yes |
|-----|-----|