




Cablofil
SB-6A-ET24-2436 AL 6H HEXP TEE 24R 2436W
Part No. P320394

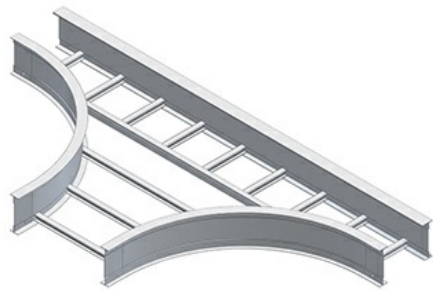

The aluminum I-beam design of ITray is perfect for industrial installations with large diameter cables in long span situations, minimizing total tray width and creating a smooth transition between straight sections and fittings. A structural offset in the sidewall creates strong, mid-span splices that need fewer supports. Each splice snaps in place and stays without holding. Additionally, only four bolts are needed for each splice reducing hardware needs by 50%. These features allow Itray to be installed up to 30% faster than standard tray.

Features & Benefits

Material: Aluminum Alloy 6063 and 5052

Finish: Plain

Bottom: LD: 1" wide rung

Construction: Welded

Tray Design: Tray construction and

Connectors: All fittings are supplied with

Fitting Heights (H): 4", 5", 6", 7"

Specifications

General Info

Product Line	Cablofil	Finish	Aluminum
UPC Number	800388166561	Country Of Origin	Mexico
Bottom Type	Solid Bottom	Application Sector	Commercial, Industrial
Type	Horizontal Other		

Dimensions

Product Width US	51.625 in	Product Weight US	25.698 lb
Product Volume US	16.781 cu ft	Product Depth US	90.0 in
Product Height US	6.241 in	Radius	24 in

Trade Programs

BAA

Yes
