




Pass and Seymour
Extra Heavy Duty Spec. Grade 347VAC Locking Toggle Switch Back and Side Wire, Gray
Part No. PS372030L

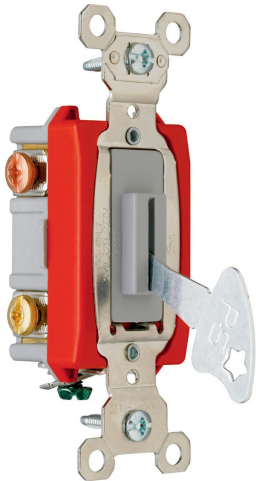

Canadian 3way Lock Switch, Back & Side Wire, 20amp 347volt, Gray

Features & Benefits

External screw-pressure-plate back and side wired. Accepts #14 - #10 AWG copper or copper-clad conductors.

Heavy-gauge one-piece copper alloy contact arm virtually eliminates contact bounce.

Cam controls fast "make" and positive "break" to minimize arcing.

Heavy-duty bumper pads for quiet operation.

High strength thermoplastic polycarbonate toggle.

Back body made of glass-reinforced nylon.

Locking support provides resistance to face and back body separation.

Oversized silver alloy contacts for long life and better heat dissipation.

Grounding terminal is standard.

Shallow design for ease of installation.

Strap nickel-plated steel with integral ground.

Auto-ground clip assures positive ground.

For covering patents, see www.legrand.us/patents.

For compatible wall plate options, from our TradeMaster unbreakable plates to our radiant screwless plates to our metal wall plates, click [here](#).

Specifications

General Info

Product Line	Pass & Seymour	Color	Gray
Country Of Origin	Mexico	Application Sector	Residential/Commercial
Standard	UL 20		

Technical Information

Actuator	Toggle	Contact Rating	20amp, 347vac
Amperage	20 A	Action	DPDT
Number of Poles	Double Pole	Voltage	347.0 V
