




Pass and Seymour
100A 4 Pole 5 Wire Fusible Mechanical Interlock
Part No. PS5100FMIR5W

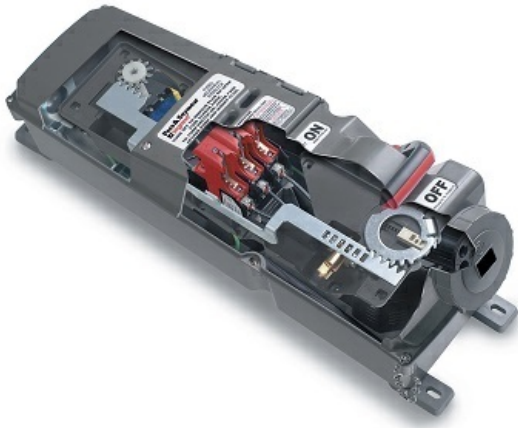

Four pole, Five wire, Fusible Mechanical Interlock Receptacle. 100 amp, 3Y, 347/600 vac.

Features & Benefits

Top or Bottom feed.

Unit shipped with no holes drilled: a top and bottom feed spot drill is provided for locating hole saw or knockout.

End user decides at installation whether top or bottom feed is appropriate.

No closure plug kits required.

Specifications

General Info

Product Line	Pass & Seymour	Color	Gray
UPC Number	785007101317	Country Of Origin	United States
Application Sector	Industrial	Standard	UL Listed

Dimensions

Product Width US	11.13 in	Product Depth US	11.06 in
Product Height US	28.31 in		

Listing Agencies / 3rd Party Agencies

cULus ListingNumber	E31169	cULus Listed	Yes
---------------------	--------	--------------	-----

Technical Information

Phase	Three	Number of Wires	5
Amperage	100 A	Number of Poles	4-Way
Voltage	347.0 V		