




Pass and Seymour  
**Pin & Sleeve Watertight 30A 3øY 120V/208V Receptacle**  
Part No. PS530R9W

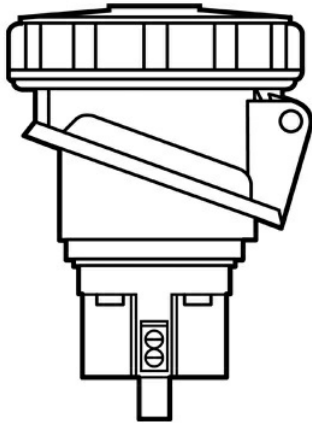

4-Pole, 5-Wire, Pin and Sleeve Receptacle, 30A, 3Y, 120/208V.

## Features & Benefits

All P&S Watertight Pin & Sleeve plugs, connectors, receptacles, and inlets bring you the features to enhance versatility, reliability, and safety.

And all feature chemical-resistant thermoplastic construction.

An exclusive, hinged cord grip eliminates loose parts that get lost.

North American products come completely ready to wire, for quick, simple installation.

Shrouded, nickel-plated, solid-brass pins provide corrosion protection and excellent conductivity.

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Gray
Country Of Origin	United States	Application Sector	Industrial
Standard	UL Listed		

### Dimensions

Product Width US	3.98 in	Product Height US	4.3 in
Product Length US	4.65 in		

### Listing Agencies / 3rd Party Agencies

cULus ListingNumber	151348	cULus Listed	Yes
---------------------	--------	--------------	-----

### Technical Information

Number of Wires	5	Amperage	30 A
Number of Poles	4-Way	Voltage	120.0 V