


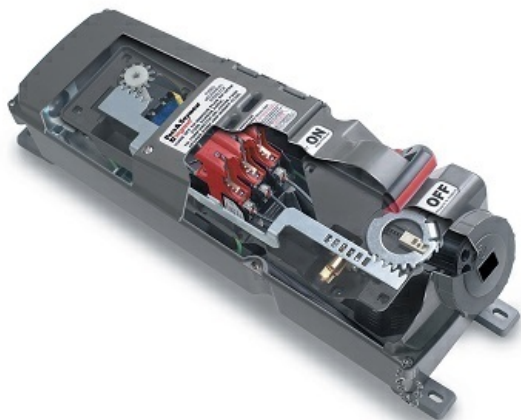

Pass and Seymour  
60A 4 Pole 5 Wire Fusible Mechanical Interlock  
Part No. PS560FMIR7W

4-Pole, 5-Wire, Fusible Mechanical Receptacle. 6 amp, 277/480V.



## Features & Benefits

Top or Bottom feed.

Unit shipped with no holes drilled: a top and bottom feed spot drill is provided for locating hole saw or knockout.

End user decides at installation whether top or bottom feed is appropriate.

No closure plug kits required.

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Gray
UPC Number	785007101232	Country Of Origin	United States
Application Sector	Industrial	Standard	UL Listed

### Dimensions

Product Width US	9.13 in	Product Depth US	9.94 in
Product Height US	24.5 in		

### Listing Agencies / 3rd Party Agencies

cULus ListingNumber	E31169	cULus Listed	Yes
---------------------	--------	--------------	-----

### Technical Information

Phase	Three	Number of Wires	5
-------	-------	-----------------	---

Amperage	60 A	Number of Poles	4-Way
Voltage	277.0 V		