




Wiremold
Plug-In Outlet Center Unit / Rack Mount 120V/15A/8 rear O/L /lighted switch/6' cord/Computer Grade Surge
Part No. R8BZ

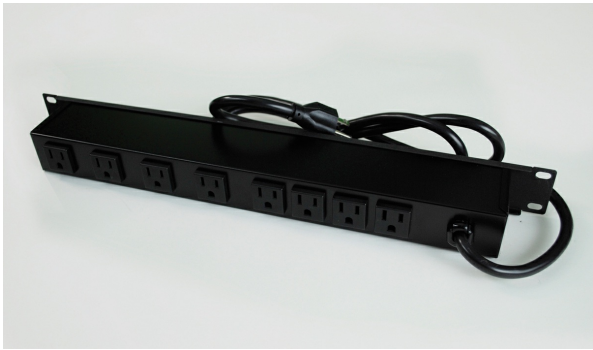

Eight rear outlets, lighted switch, 15A. Receptacles rotated 90 degrees and 4 outlets spaced to accommodate transformers. 6' (1.8m) cord. Perma Power computer grade surge protection.

Features & Benefits

Eight rear outlets, lighted switch, 15A. Receptacles rotated 90 degrees and 4 outlets spaced to accommodate transformers. 6' (1.8m) cord. Perma Power computer grade surge protection.

Specifications

General Info

| | | | |
|-------------------|---|--------------------|------------------------|
| Product Line | Wiremold | UPC Number | 786776012200 |
| Country Of Origin | China | Application Sector | Residential/Commercial |
| Standard | cULus Recognized: File E66421: Guide XBYS2, XUHT2, VZCA12 | Type | PIOC |

Dimensions

| | | | |
|-------------------|---------|-------------------|---------|
| Product Width US | 19.0 in | Product Height US | 2.57 in |
| Product Length US | 1.75 in | | |

Additional Information

| | |
|-----------------|-----|
| RoHS Conformant | Yes |
|-----------------|-----|

Technical Information

| | | | |
|---------------|--------------|----------------------|---|
| Phase | Single Stage | Frequency Rating | +35dB Hz |
| Connection | Cord-ended | Class | 75 |
| Amperage | 15 A | Short Circuit Rating | 36000 Amps [12000 Amps L-N 12000 Amps L-G 12000 Amps N-G] |
| Response Time | <1 ns | Mounting Type | Rack Mounting |
| Mounting | Yes | Type of Indicators | Light |
| Voltage | 120.0 V | | |