




Wiremold  
Plug-In Outlet Center Unit / Rack Mount 120V/15A/8 rear O/L /lighted switch/6' cord/Computer Grade Surge  
Part No. R8BZ

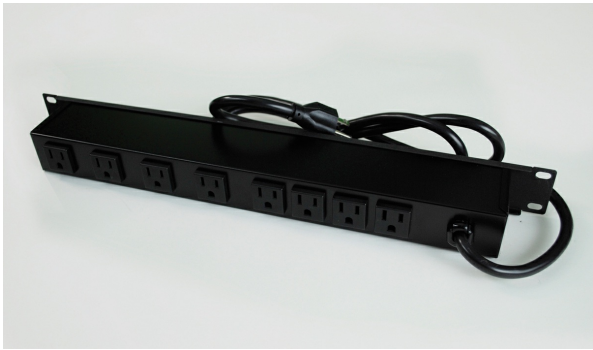

Eight rear outlets, lighted switch, 15A. Receptacles rotated 90 degrees and 4 outlets spaced to accommodate transformers. 6' (1.8m) cord. Perma Power computer grade surge protection.

Features & Benefits

Eight rear outlets, lighted switch, 15A. Receptacles rotated 90 degrees and 4 outlets spaced to accommodate transformers. 6' (1.8m) cord. Perma Power computer grade surge protection.

Specifications

General Info			
Product Line	Wiremold	UPC Number	786776012200
Country Of Origin	China	Application Sector	Commercial, Residential
Standard	cULus Recognized: File E66421: Guide XBY52, XUHT2, VZCA12	Warranty Type	1-Year from Installation or 2-Years from Day of Sale
Type	PIOC		

Dimensions			
Product Width US	19.0 in	Product Weight US	3.1 lb
Product Height US	2.57 in	Product Length US	1.75 in

Listing Agencies / 3rd Party Agencies	
cULus Listed	Yes

Additional Information	
RoHS Compliant	Yes

Technical Information			
Phase	Single Stage	Connection	Cord-ended
Class	75	Amperage	15 A
Short Circuit Rating	36000 Amps [12000 Amps L-N 12000 Amps L-G 12000 Amps N-G]	Response Time	<1 ns
Mounting Type	Rack Mounting	Mounting	Yes
Type of Indicators	Light	Voltage	120.0 V