




Ortronics  
28awg Reduced diameter C6A/10G channel cord Yellow 20FT  
Part No. RDC61020-04

RDC610 Modular Patch Cord, yellow, 20', reduced diameter, 28 AWG, cat6a channel four-pair UTP stranded PVC/CM.

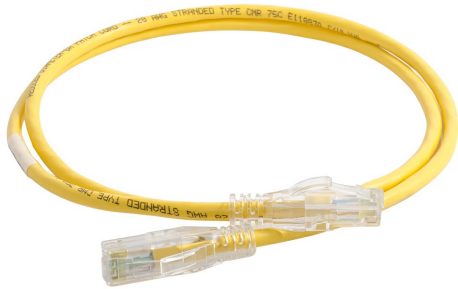

## Features & Benefits

- Each cord is 100% factory tested: Ensures every cord shipped support Category 6a channel specifications.
- Reduced cable diameter: Tighter bend radiuses & occupy less cable management space supporting more airflow
- Premium plug designed for reduced OD 28AWG patch cable: Protects performance through the plug termination
- Snagless plug design: Protects plugs when routing through cable managers or pathways.
- Premium 28AWG conductor cordage: Reliable performance and durable cord life.
- Backwards compatible to Category 6, and 5e: Supports lower category installations and components.
- Improved cable flexibility: Supports simple routing and cable management

## Specifications

### General Info

Product Line	Ortronics	UPC Number	662875854357
Country Of Origin	Mexico	Application Sector	Commercial/Industrial
Standard	FCC	Type	Reduced Diameter Patch Cords

### Dimensions

Product Length US	20.0 FT
-------------------	---------

### Additional Information

RoHS Conformant	Yes	Product Environmental Profile	Yes
-----------------	-----	-------------------------------	-----