




radiant Collection
radiant® Single-Pole 3-Way Vacancy Sensor, White
Part No. RRW600VW

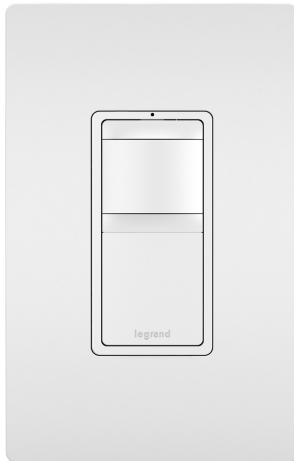

Never worry about leaving the lights on, with the radiant® Vacancy Sensor. It automatically shuts off when a room is empty, and includes an adjustable delay setting of up to 20 minutes to match your needs. Designed for ease and style, it features a built-in locator light, and the sleek, clean lines of radiant® for a sophisticated touch. Made exclusively for use with screwless Wall Plates from the radiant® Collection, sold separately.

Features & Benefits

- Passive infrared (PIR) sensor switch technology with 180° coverage up to 600 sq. ft. Rated for up to 600W (5A) of LED lighting.
 - Turn the light on when you enter, and let it turn itself off automatically after you leave for true convenience. Perfect for bathrooms, hallways, closets, garages, and more.
 - Features an adjustable time delay to off after no motion is detected. Delay settings range from 30 seconds to 20 minutes after the room is vacated (default 20 minute delay).
 - Replace any basic light or fan switch in 15 minutes or less. Supports single pole and multi-location installs. No neutral required.
 - More color options available to fit any style, including finishes to match current hardware and lighting trends.
- Works with virtually any bulb/fixture, including: LED, incandescent, fluorescent, compact fluorescent (CFL), magnetic low-voltage (MLV) and electronic low-voltage (ELV), 1/6 hp.
 - Locator light illuminates when switch is off, emitting a soft glow to help you find it in the dark.
 - Manual ON/Auto OFF functionality. Meets California Title 24 requirements for automatic off lighting control.
 - Complete the look with a sleek, screwless radiant® Wall Plate, and coordinate with other designer switches and outlets available from the radiant® Collection.

Specifications

General Info

Product Line	Pass & Seymour	Color	White
Country Of Origin	China	Features	Motion Sensor
Switch Type	Motion Sensor	Application Sector	Residential

Dimensions

Product Width US	1.69 in	Product Depth US	1.88 in
------------------	---------	------------------	---------

Product Height US 2.63 in

Listing Agencies / 3rd Party Agencies

cULus Listed Yes

Technical Information

Target Size 180 deg Response Frequency 60 Hz

Sensor Type Vacancy Amperage 5 A

Number of Poles Single Pole 3-Way Indoor/Outdoor Indoor

Wattage 600 W Mounting Type Box

Sensing Range 600 sq ft Voltage 120 V

Sensitivity 60Hz Load 120VAC
