




Pass and Seymour
3-Gang 430 Stainless Steel Wall Plate, 3 Toggle Switch Openings
Part No. SL3

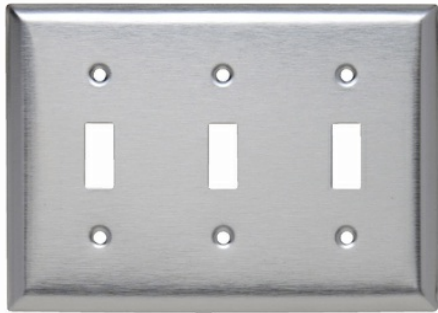

Smooth Metal Wall Plate 3-Gang Toggle 430 Stainless Steel

Features & Benefits

Type 430 Stainless Steel, magnetic: .032" nominal thickness.	Brushed finish.
Less corrosion-resistant than Type 302, but ideal for general service in high abuse applications in industrial plants, commercial, and industrial buildings.	Constructed of corrosion-resistant stainless steel, brass, aluminum, chrome, brushed bronze, or galvanized steel.
Standard, Jumbo, and Tandem plates available, as well as special Panel plates up to 5-gangs high and 10-gangs wide.	Packaged in protective film, with finish-matching screws.
Variety of special plated finishes.	Paintable to match plastic plates.
Can be silk-screened or engraved, and custom punched with over 300 opening styles.	For covering patents, see www.legrand.us/patents .

Specifications

General Info

Product Line	Pass & Seymour	Color	Stainless Steel
Finish	Metallic	UPC Number	785007657975
Country Of Origin	United States	Wall Plate Size	Standard Size
Wall Plate Type	Toggle Switch	Application Sector	Commercial, Residential
Warranty Type	1-Year Limited Warranty	Type	Wall Plate

Dimensions

Product Width US	6.375 in	Product Depth US	0.2 in
Product Height US	4.5 in		
Listing Agencies / 3rd Party Agencies			
cULus ListingNumber	143223	cULus Listed	Yes
Additional Information			
Product Environmental Profile	Yes		
Technical Information			
Thickness	0.032 in	Number of Gangs	3
Indoor/Outdoor	Indoor	Mounting Type	Box Mounted
Orientation	Vertical		