




Pass and Seymour
Duplex Receptacle Openings, Two Gang, 430 Stainless Steel
Part No. SL82

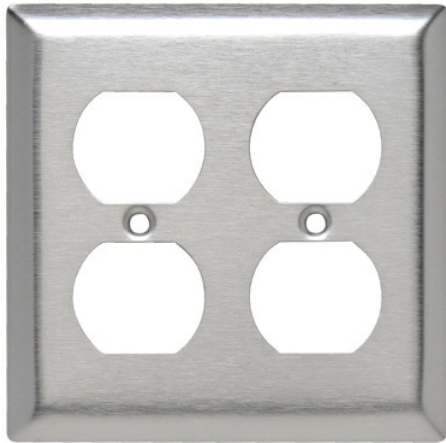

Smooth Metal Wall Plate 1-Gang Duplex 430 Stainless Steel

Features & Benefits

Type 430 Stainless Steel, magnetic: .032" nominal thickness.

Brushed finish.

Less corrosion-resistant than Type 302, but ideal for general service in high abuse applications in industrial plants, commercial, and industrial buildings.

Constructed of corrosion-resistant stainless steel, brass, aluminum, chrome, brushed bronze, or galvanized steel.

Standard, Jumbo, and Tandem plates available, as well as special Panel plates up to 5-gangs high and 10-gangs wide.

Packaged in protective film, with finish-matching screws.

Variety of special plated finishes.

Paintable to match plastic plates.

Can be silk-screened or engraved, and custom punched with over 300 opening styles.

For covering patents, see www.legrand.us/patents.

Specifications

General Info

Product Line	Pass & Seymour	Country Of Origin	United States
Application Sector	Residential/Commercial		

Dimensions

Product Width US	4.56 in	Product Depth US	0.2 in
Product Height US	4.5 in		

Listing Agencies / 3rd Party Agencies

cULus ListingNumber	143223	cULus Listed	Yes
---------------------	--------	--------------	-----

Technical Information

Cutout	Receptacle	Thickness	0.032 in
--------	------------	-----------	----------

Number of Gangs	2
-----------------	---
