




Vantage  
Standard Load Dimmer Station (DIN)  
Part No. SLDS4-DIN

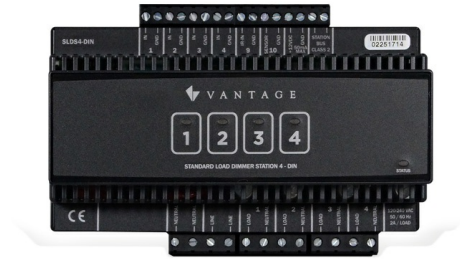

The Standard Load Dimmer Station is used to incrementally expand the control and dimming capacity of the Vantage automation and lighting control system. It is designed to easily install on standard 35 mm DIN rail and has connections to control up to four 480 Watt loads at 240 VAC. The Dimmer Station can communicate with a Vantage master through a two-wire bus or a small connector on its side to orchestrate complex and elegant lighting scenes. Each load can also be independently controlled from the four buttons on the front of the station.

## Features & Benefits

Features six contact inputs for control of additional auxiliary devices

Dims incandescent, and magnetic loads

Displays the operating status with LED indicators

## Specifications

### General Info

Product Line	Vantage	UPC Number	804428120780
Country Of Origin	China	Installation Location	Enclosure
Application Sector	Commercial, Residential	Warranty Type	5-Year
Type	Dimmer Station		

### Dimensions

Product Width US	5.0 in	Product Weight US	1.55 lb
Product Height US	3.0 in	Product Length US	7.0 in

### Technical Information

Compatibility	InFusion	Seismic Tested	No
Indoor/Outdoor	Indoor	Mounting Type	DIN Rail
Operating Temperature	0°-35°C, 32°-95°F		

