


Plate Plastic 2-Gang Toggle and Sierraplex Without Line

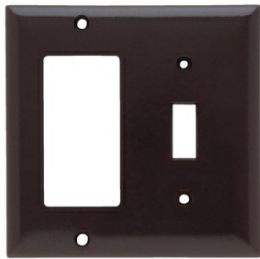

## Features & Benefits

Molded of non-combustible mar-proof material.

Seven standard colors available -- Ivory, White, Brown, Gray, Black, Red, and Light Almond.

Resistant to discoloration, grease, oil, solvent, and moisture.

Available in 'SP' series in Standard, Junior-Jumbo, and Jumbo sizes.

Individually wrapped with color-matching screws.

Nominal thickness, .070 inch.

## Specifications

### General Info

|                   |                                       |                    |                           |
|-------------------|---------------------------------------|--------------------|---------------------------|
| Product Line      | Pass & Seymour                        | Color              | Brown                     |
| Finish            | Matte                                 | UPC Number         | 785007680973              |
| Country Of Origin | Mexico                                | Features           | Combination               |
| Wall Plate Type   | Combination, Decorator, Toggle Switch | Application Sector | Commercial, Residential   |
| Standard          | CSA, UL514                            | Warranty Type      | Limited Lifetime Warranty |
| Type              | Wall Plate                            |                    |                           |

### Dimensions

|                   |         |                  |        |
|-------------------|---------|------------------|--------|
| Product Width US  | 4.56 in | Product Depth US | 0.2 in |
| Product Height US | 4.5 in  |                  |        |

### Listing Agencies / 3rd Party Agencies

|            |     |                 |       |
|------------|-----|-----------------|-------|
| CSA Listed | Yes | CSA File Number | 17695 |
|------------|-----|-----------------|-------|

### Additional Information

|                               |     |
|-------------------------------|-----|
| Product Environmental Profile | Yes |
|-------------------------------|-----|

### Technical Information

|                 |                      |               |                |
|-----------------|----------------------|---------------|----------------|
| Cutout          | Toggle and Decorator | Thickness     | 0.07 in        |
| Number of Gangs | 2                    | Wire Size     | #14 - #10 AWG  |
| Indoor/Outdoor  | Indoor               | Mounting Type | Exposed Screws |

---

Orientation

Horizontal

---