




Pass and Seymour  
Junior Jumbo 1-Gang Thermoset Wall Plate, 1 Decorator Opening, Ivory  
Part No. SPJ26I

Smooth Wall Plate Junior-Jumbo 1-Gang Decorator

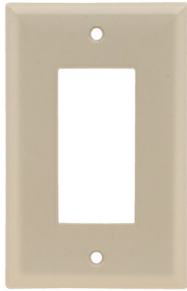

## Features & Benefits

Molded of non-combustible mar-proof material.

Available in 'SP' series in Standard, Junior-Jumbo, and Jumbo sizes.

Seven standard colors available -- Ivory, White, Brown, Gray, Black, Red, and Light Almond.

Individually wrapped with color-matching screws.

Resistant to discoloration, grease, oil, solvent, and moisture.

Nominal thickness, .070 inch.

## Specifications

### General Info

|                    |                         |                 |              |
|--------------------|-------------------------|-----------------|--------------|
| Product Line       | Pass & Seymour          | Color           | Ivory        |
| Finish             | Matte                   | UPC Number      | 785007680645 |
| Country Of Origin  | Mexico                  | Construction    | Plastic      |
| Wall Plate Size    | Junior-Jumbo            | Wall Plate Type | Decorator    |
| Application Sector | Commercial, Residential | Standard        | CSA, UL514   |
| Warranty Type      | 1-Year Limited Warranty | Type            | Wall Plate   |

### Dimensions

|                   |          |                  |        |
|-------------------|----------|------------------|--------|
| Product Width US  | 3.125 in | Product Depth US | 0.2 in |
| Product Height US | 4.87 in  |                  |        |

### Listing Agencies / 3rd Party Agencies

|            |     |                 |       |
|------------|-----|-----------------|-------|
| CSA Listed | Yes | CSA File Number | 17695 |
|------------|-----|-----------------|-------|

Additional Information

Product Environmental Profile      Yes

Technical Information

|                |          |                 |             |
|----------------|----------|-----------------|-------------|
| Thickness      | 0.07 in  | Number of Gangs | 1           |
| Indoor/Outdoor | Indoor   | Mounting Type   | Box Mounted |
| Orientation    | Vertical |                 |             |