


Smooth Metal Wall Plate, Jumbo 4gang Toggle, 302/304 Stainless Steel

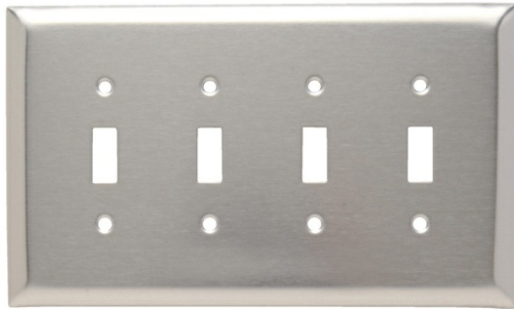

Features & Benefits

- Type 302/304 Stainless Steel, non-magnetic: .032" nominal thickness. Brushed finish.
- This alloy contains 18% chromium and 8% nickel for superior resistance to corrosion. Recommended for use in food processing plants, dairies, chemical plants, and other industrial, institutional, and commercial applications where corrosive atmospheres exist.
- Standard, Jumbo, and Tandem plates available, as well as special Panel plates up to 5-gangs high and 10-gangs wide. Packaged in protective film, with finish-matching screws.
- Variety of special plated finishes. Paintable to match plastic plates.
- Can be silk-screened or engraved, and custom punched with over 300 opening styles.

Specifications

General Info

UPC Number	785007136760	Country Of Origin	United States
------------	--------------	-------------------	---------------

Product Line	Pass & Seymour	Application Sector	Residential/Commercial
--------------	----------------	--------------------	------------------------

Standard	UL 514
----------	--------

Listing Agencies / 3rd Party Agencies

cULus Listed	Yes
--------------	-----

Technical Information

Cutout	Toggle	Thickness	0.032 in
--------	--------	-----------	----------