




Ortronics  
Clarity 6 TracJack, T568A/B, 180 degree, Orange  
Part No. TJ600-43

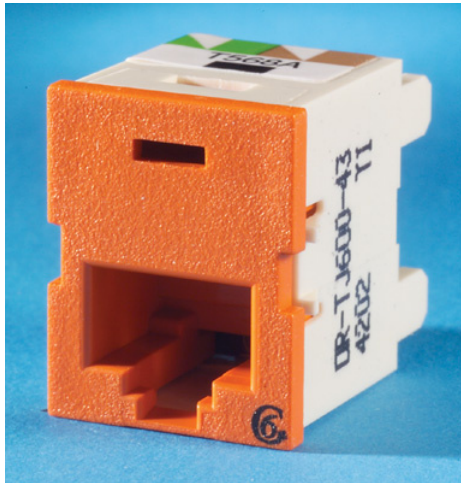

Clarity 6a, 6 & 5e TracJacks, ETL verified to TIA Category 6a, 6 & 5e component specification. Front-loading and front removable. New universal T568A/B wiring label and tapered wiring towers simplify termination. Center tuned to Clarity patch cords for optimum performance.

TracJack® modules combine the ease and reliability of a front-loading individual jack with 110 termination.

## Features & Benefits

ETL Verified to Category 6A component standard: Ensures standards compliance.

Easy to follow universal wiring label: Quick and user-friendly, eliminates confusion.

Center tuned design: Transparent interface with Clarity 6A/10G cords

Easy lace IDC housing: Reduces wiring time

Standard TracJack footprint: Fits in all TracJack faceplates and housings

Icon compatible, C6A marking on jack face: Supports 606 designation requirements

## Specifications

### General Info

Product Line	Ortronics	UPC Number	662875437901
Country Of Origin	Mexico	Application Sector	Commercial/Industrial
Standard	TIA-568.2-D, UL 1863, IEEE 802.3af / 802.3at, 802.3bt Type 3 and Type 4, FCC part 68 Subpart F, IEC-603-7 compliant	Type	Jack

### Dimensions

Product Width US	0.73 in	Product Depth US	1.1 in
Product Height US	0.92 in		

### Additional Information

RoHS Conformant	Yes	Product Environmental Profile	Yes
-----------------	-----	-------------------------------	-----

---

## Technical Information

---

IDC Wire Gauge      22-26 AWG

---