


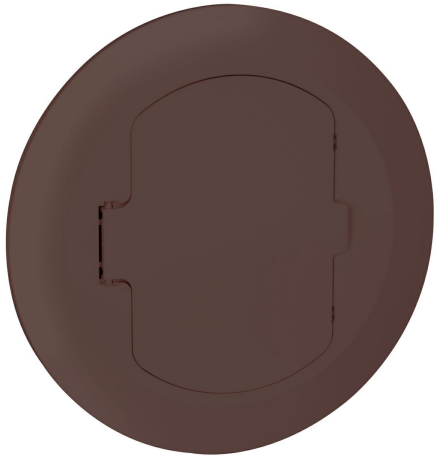

Pass and Seymour  
Tamper-Resistant Thermoplastic Floor Box Cover, Brown  
Part No. TM1542TRBR



Thermoplastic Cover Includes 15A 125A Decorator receptacle, matching detachable and replaceable hinged door threaded device-mounting holes drill guides for low-voltage poke-through holes accepts any Decorator device mounts on carpeting, hardwood, linoleum, tile floors Four mounting/leveling screws. .For detailed Tamper-Resistant receptacle information, visit our Tamper-Resistant Receptacles page.

## Features & Benefits

Tamper-Resistant shutters let plugs in, keep other things out.

Hinged door is removable and easily replaceable.

Durable construction, impact, and scratch resistant PVC construction.

Standard Decorator opening that accepts GFCI, TVSS, DataCom, or other Decorator devices.

Auto/Clamps and knockouts on both sides of box.

Meets UL514(c) scrub water exclusion test.

Threaded device mounting holes.

Simple mounting box, fits into a 4 3/4 inch hole and mounts with 3 screws included.

Ready for low-voltage wiring, drill guides on underside of cover.

UL and cUL Listed. Captive screws on TM1542 Series -- screws will not be lost -- new.

Made in USA.

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Brown
Country Of Origin	United States	Application Sector	Residential/Commercial
Standard	UL listed		

### Dimensions

Cubic Capacity	38 cu in
----------------	----------

### Technical Information

---

Is Tamper-Resistant	Yes	Number of Outlets	1
---------------------	-----	-------------------	---

---