




Pass and Seymour
Tamper-Resistant Thermoplastic Floor Box Cover, Brown
Part No. TM1542TRBR

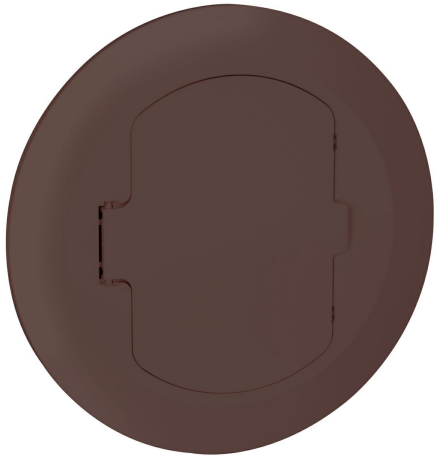

Thermoplastic Cover Includes 15A 125A Decorator receptacle, matching detachable and replaceable hinged door threaded device-mounting holes drill guides for low-voltage poke-through holes accepts any Decorator device mounts on carpeting, hardwood, linoleum, tile floors Four mounting/leveling screws. .For detailed Tamper-Resistant receptacle information, visit our Tamper-Resistant Receptacles page.

Features & Benefits

Tamper-Resistant shutters let plugs in, keep other things out.

Hinged door is removable and easily replaceable.

Durable construction, impact, and scratch resistant PVC construction.

Standard Decorator opening that accepts GFCI, TVSS, DataCom, or other Decorator devices.

Auto/Clamps and knockouts on both sides of box.

Meets UL514(c) scrub water exclusion test.

Threaded device mounting holes.

Simple mounting box, fits into a 4 3/4 inch hole and mounts with 3 screws included.

Ready for low-voltage wiring, drill guides on underside of cover.

UL and cUL Listed. Captive screws on TM1542 Series -- screws will not be lost -- new.

Made in USA.

Specifications

General Info

| | | | |
|--------------------|-------------------------|-------------------|---------------|
| Product Line | Pass & Seymour | Color | Brown |
| UPC Number | 785007108835 | Country Of Origin | United States |
| Application Sector | Commercial, Residential | Standard | UL listed |

Dimensions

| | |
|----------------|--------------------|
| Cubic Capacity | 38 in ³ |
|----------------|--------------------|

Technical Information

| | | | |
|---------------------|-----|-------------------|---|
| Is Tamper-Resistant | Yes | Number of Outlets | 1 |
|---------------------|-----|-------------------|---|
